




SNFX-TBZ Hexalobular Socket Flat Head Cap Screws

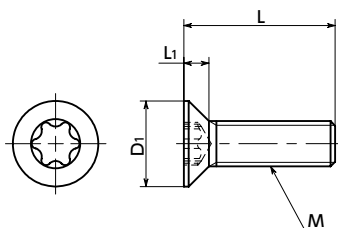

Material/Finish



	SNFX-TBZ
Main Body	Steel Black Trivalent Chromate Treatment
Strength Class	4.8 Equivalent



- Hexalobular socket shapes*1 are designed to withstand high tightening torque compared to cross-recesses.
- Recesses are unlikely to be damaged due to tightening, allowing safe and secure tightening to be performed.

*1: The hexalobular shape is prescribed by JIS B 1015: 2008(ISO 10664: 2005)"Hexalobular internal driving feature for bolts and screws".

Application

Prevention of damage to screw heads
Reliable tightening

Unit : mm

Part Number	M (Coarse)		L												D1	L1	Hexalobular Socket No.	Mass (g)	Qty per Pack
	Nominal of Thread	Pitch	5	6	8	10	12												
SNFX-M3-TBZ	M3	0.5													6	1.75	10	0.32 - 0.60	20
SNFX-M4-TBZ	M4	0.7													8	2.3	20	0.90 - 1.2	20
SNFX-M5-TBZ	M5	0.8													10	2.8	25	1.9 - 2.2	20
SNFX-M6-TBZ	M6	1													12	3.4	30	2.5 - 7.5	20

- When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

Related Products

SKX Hexalobular Wrench



SKX-N Hexalobular Wrench for Extremely Limited Access Spaces



SKXB Hexalobular Short Bit



SRD Magnet Screwdriver



Part Number Specification

SNFX-M6-20-TBZ



Individual Sales	Cleanroom Wash & Packaging	Screw Length Adjustment	Vibration Resistant	Modification process for captive use
Available / Add'l charge	Available / Add'l charge	Available / Add'l charge	Available / Add'l charge	Not Available