




SECS Super Ultra Low Profile Cross Recessed Machine Screws

Protrusion SUS Stainless steel

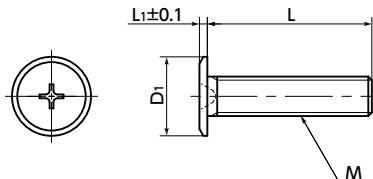

● Material/Finish

| | SECS | RoHS |
|----------------|-------------------------------|------|
| Main Body | SUSXM7 (Equivalent to SUS304) | |
| Strength Class | A2 - 50 | |



- Cross recessed head cap screws with extra low profile.
- For space-saving of equipment/devices and applications with limited overhead space.
- **SEQS**, with special cross recesses helping to prevent cam-out, are also available. The lineup includes some M3/M4 L dimensions.

● Application

Reducing the size of equipment and devices

| Part Number | M (Coarse) | | | | | | | | | | D1 | L1 | Cross-recessed Socket No. | Max. Tightening Torque (N·m)*1 | Mass (g) | Unit : mm Qty per Pack | |
|----------------|-------------------|-------|---|---|---|---|----|----|----|----|----|----|------------------------------|-----------------------------------|----------|---------------------------|----------------|
| | Nominal of Thread | Pitch | L | | | | | | | | | | | | | | |
| SECS-M3 | M3 | 0.5 | 4 | 5 | 6 | 8 | 10 | 12 | 16 | 20 | 25 | 30 | 6 | 0.8 | 1 | 0.63 | 0.32 - 0.95 50 |
| SECS-M4 | M4 | 0.7 | | | 6 | 8 | 10 | 12 | 16 | 20 | 25 | | 8 | 0.9 | 2 | 1.05 | 0.97 - 1.7 50 |
| SECS-M5 | M5 | 0.8 | | | 6 | 8 | 10 | 12 | 16 | 20 | 25 | 30 | 9 | 1 | 2 | 1.47 | 1.9 - 2.9 50 |
| SECS-M6 | M6 | 1 | | | | | 10 | 12 | 16 | 20 | 25 | 30 | 10 | 1.2 | 2 | 3 | 3.4 - 6 20 |

*1 : Values in chart are for reference only. They are not guaranteed values.

● When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

● Part Number Specification

SECS-M3-8

1 2

| Individual Sales | Cleanroom Wash & Packaging | Screw Length Adjustment | Vibration Resistant | Modification process for captive use |
|--------------------------|----------------------------|--------------------------|--------------------------|--------------------------------------|
| Available / Add'l charge | Available / Add'l charge | Available / Add'l charge | Available / Add'l charge | Not Available |