




SHNS-LP Thin Hex Nuts

Protrusion SUS Stainless steel

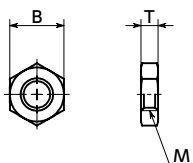

Material/Finish



	SHNS-LP
Main Body	Stainless Steel (A2 Equivalent)

- Thin hex nuts conforming to ISO 4035.
- For space-saving of equipment/devices and applications with limited space.

Application

Reducing the size of equipment and devices

Unit : mm

Part Number	M (Coarse)		B	T	Mass (g)	Qty per Pack
	Nominal of Thread	Pitch				
SHNS-M1.6-LP	M1.6	0.35	2.2	1	0.05	1
SHNS-M2-LP	M2	0.4	4	1.2	0.08	20
SHNS-M2.5-LP	M2.5	0.45	5	1.6	0.17	20
SHNS-M3-LP	M3	0.5	5.5	1.8	0.21	20
SHNS-M3.5-LP	M3.5	0.6	6	2	0.27	20
SHNS-M4-LP	M4	0.7	7	2.2	0.47	20
SHNS-M5-LP	M5	0.8	8	2.7	0.6	20
SHNS-M6-LP	M6	1	10	3.2	1.3	20
SHNS-M8-LP	M8	1.25	13	4	2.8	20
SHNS-M10-LP	M10	1.5	17	5	6.3	10
SHNS-M12-LP	M12	1.75	19	6	9.1	10
SHNS-M14-LP	M14	2	22	7	13.5	1
SHNS-M16-LP	M16	2	24	8	17.2	1

- When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

Part Number Specification

SHNS-M5-LP



1 Individual Sales	Cleanroom Wash & Packaging	Screw Length Adjustment	Vibration Resistant	Modification process for captive use
Available / Add'l charge	Available / Add'l charge	Not Available	Not Available	Not Available