




SNZ2-TBZ Cross Recessed Micro Pan Head Screws - Type 0 - 2

Miniature Size

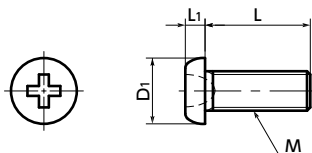

Material/Finish



	SNZ2-TBZ
Main Body	Steel Black Trivalent Chromate Treatment



- Miniature screws for precision instruments (No. 0 Class 2).
- M1.4 - M2.6.
- Pan head machine screw type with low head height. For applications with limited overhead space.
- Application

For making devices and equipment more compact
Compact precision equipment

Unit : mm

Part Number	M (Coarse)		L											D1	L1	Cross-recessed Socket No.	Max. Tightening Torque (N·m)	Mass (g)	Qty per Pack
	Nominal of Thread	Pitch		2	2.5	3	3.5	4	5	6	8	10	12						
SNZ2-M1.4-TBZ	M1.4	0.3		2	2.5	3	3.5	4	5	6	8	10	12	2.5	0.5	0	0.07	0.03 - 0.1	50
SNZ2-M1.6-TBZ	M1.6	0.35		2	2.5	3	3.5	4	5	6	8	10	12	2.8	0.55	0	0.11	0.04 - 0.12	50
SNZ2-M1.7-TBZ	M1.7	0.35		2	2.5	3		4		6	8	10	12	3.0	0.5	0	0.14	0.05 - 0.14	50
SNZ2-M2-TBZ	M2	0.4	1.5	2	2.5	3	3.5	4	5	6	8	10	12	3.5	0.6	0	0.22	0.06 - 0.21	50
SNZ2-M2.5-TBZ	M2.5	0.45				3		4	5	6	8			4.3	0.9	0	0.46	0.16 - 0.3	50
SNZ2-M2.6-TBZ	M2.6	0.45			2.5	3	3.5	4	5	6	8	10	12	4.5	0.8	0	0.53	0.16 - 0.39	50

- When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

Part Number Specification

SNZ2-M2-3-TBZ



Individual Sales	Cleanroom Wash & Packaging	Screw Length Adjustment	Vibration Resistant	Modification process for captive use
Available / Add'l charge	Available / Add'l charge	Not Available	Available / Add'l charge	Not Available