




SNZ2S Cross Recessed Micro Pan Head Screws - Type 0 - 2

Miniature Size **SUS** Stainless steel

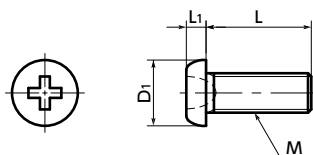

• Material/Finish



	SNZ2S
Main Body	Stainless Steel



- Miniature screws for precision instruments (No. 0 Class 2).
- M1.4 - M2.
- Pan head machine screw type with low head height. For applications with limited overhead space.

• Application

For making devices and equipment more compact
Compact precision equipment

Unit : mm

Part Number	M (Coarse)		L										D1	L1	Cross-recessed Socket No.	Max. Tightening Torque (N·m)	Mass (g)	Qty per Pack	
	Nominal of Thread	Pitch																	
SNZ2S-M1.4	M1.4	0.3	1.5	2	2.5	3	3.5	4	5	6	8	10	2.5	0.5	0	0.07	0.03 - 0.1	50	
SNZ2S-M1.6	M1.6	0.35		2	2.5	3	3.5	4	5	6	8	10	2.8	0.55	0	0.1	0.04 - 0.12	50	
SNZ2S-M1.7	M1.7	0.35		2		3	3.5	4	5		8	10	3.0	0.5	0	0.14	0.05 - 0.14	50	
SNZ2S-M2	M2	0.4		2	2.5	3	3.5	4	5	6	8	10	12	3.5	0.6	0	0.22	0.07 - 0.21	50

- When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

• Part Number Specification

SNZ2S-M2-3



1 Individual Sales	Cleanroom Wash & Packaging	Screw Length Adjustment	Vibration Resistant	Modification process for captive use
Available / Add'l charge	Available / Add'l charge	Not Available	Available / Add'l charge	Not Available