




SPC-S-BK Plastic Slotted Set Screws - PC

Lightweight Electrical Insulation

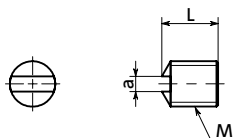

- PC (polycarbonate) slotted setscrews.
- PC (polycarbonate) has the highest shock resistance of engineering plastics.
- Allowable operating temperature*1 (min./max.): -40°C/115°C
- PC has low water absorbency and excellent weather resistance.
- For the properties and precautions for use of plastic screws, see "Properties of Plastic Screws."

● Application

Electrical and electronic equipment

● Material/Finish



	SPC-S-BK
Main Body	PC (Polycarbonate) (Black)
Heat Resistance Temperature*1	115°C

*1: This is the value for the resin material. The operating temperature of the product changes with performance conditions such as tightening torque.

Unit : mm

Part Number	M (Coarse)		L	a	Mass (g)	Qty per Pack
	Nominal of Thread	Pitch				
SPC-M6-S-BK	M6	1	6	1.5	0.25	20
SPC-M6-S-BK(1000)	M6	1	6	1.5	0.25	1000

- When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

● Part Number Specification

SPC-M6-6-S-BK



Individual Sales	Cleanroom Wash & Packaging	Screw Length Adjustment	Vibration Resistant	Modification process for captive use
Available / Add'l charge	Available / Add'l charge	Not Available	Not Available	Not Available