




SRS55 System 5 Screws

Miniature Size Tamper Resistance SUS Stainless steel

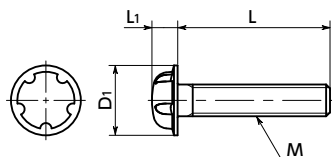

Material/Finish



	SRS55
Main Body	SUSXM7
Strength Class	Equivalent to A2-50



- Head has a special round shape with 5 grooves.
- This prevents mounting and removing with regular tools, including pliers.
- Install and remove with **SKRS5K** Dedicated Bits and **SRD** Dedicated Magnetic Screwdriver.
- Application

Equipment/devices disassembly/tampering prevention
Theft prevention for outdoor facilities
Security measures
Safety measures

Unit : mm																			
Part Number	M (Coarse)		L										D1	L1	Bit Part No.	Screwdriver Part No.	Mass (g)	Qty per Pack	
	Nominal of Thread	Pitch																	
SRS55-M2	M2	0.4	3	4	5	6	8	10	12	16		4.5	1.45	SKRS5K-2	SRD-6.35	0.16 - 0.38	10		
SRS55-M2.5	M2.5	0.45	3	4	5	6	8	10	12	16	20	5.5	2.02	SKRS5K-3	SRD-6.35	0.29 - 0.78	10		
SRS55-M2.6	M2.6	0.45	3	4	5	6	8	10	12	16	20	5.5	2.02	SKRS5K-3	SRD-6.35	0.33 - 0.85	10		

Unit : mm

- When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

Related Products

SKRS5K applicable bits are available.



Dedicated magnetic screwdrivers **SRD** are available.



Part Number Specification

SRS55-M2-16

1 2

Individual Sales	Cleanroom Wash & Packaging	Screw Length Adjustment	Vibration Resistant	Modification process for captive use
Available / Add'l charge	Available / Add'l charge	Available / Add'l charge	Available / Add'l charge	Not Available