


SNSS-PC Socket Head Cap Screws - Specialized Chemical Polishing



Vacuum
 Cleanroom wash & packaging
 SUS Stainless steel

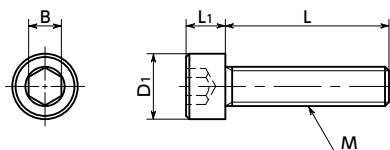

Material/Finish



	SNSS-PC
Main Body	SUSXM7 (Equivalent to SUS304) Special Chemical Polishing
Strength Class	A2 - 70



- Stainless steel hex socket head cap screws.
- Special chemical polishing treatment improves the surface roughness. Outgas quantity is extremely low. Ideal for use in medium vacuum environments.
- Cleanroom washing/cleanroom packing provided.
- Application

FPD production equipment / Semiconductor manufacturing equipment / Electron microscopes

Unit : mm

Part Number	M (Coarse)		L											D1	L1	B	Mass (g)	Qty per Pack
	Nominal of Thread	Pitch																
SNSS-M3-PC	M3	0.5	5	6	8	10	12	16					5.5	3	2.5	0.67 - 1.2	20	
SNSS-M4-PC	M4	0.7	5	6	8	10	12	16	20	25			7	4	3	1.4 - 3.2	20	
SNSS-M5-PC	M5	0.8		6	8	10	12	16	20	25			8.5	5	4	2.2 - 4.8	20	
SNSS-M6-PC	M6	1			8	10	12	16	20	25	30		10	6	5	4.3 - 8.3	20	
SNSS-M8-PC	M8	1.25				12	16	20	25	30	35		13	8	6	11 - 19	10	

- When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

Part Number Specification

SNSS-M5-12-PC

Individual Sales	Cleanroom Wash & Packaging	Screw Length Adjustment	Vibration Resistant	Modification process for captive use
Available / Add'l charge	Cleanroom washed and packed	Not Available	Not Available	Not Available