




# SPPVC-N Plastic Screws - Hex Head Nuts - H-PVC

Chemical-proof

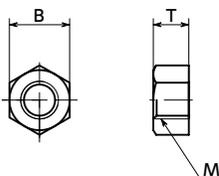

## Material/Finish



SPPVC-N	
Main Body	H-PVC (Hard Polyvinyl Chloride) (Gray)
Heat Resistance Temperature*1	60°C

\*1 : This is the value for the resin material. The operating temperature of the product changes with performance conditions such as tightening torque.

- Has excellent chemical resistance against organic solvents as well as halogen compounds such as hydrogen sulfide and bromine.
- You can use it even in environments where metal screws cannot be used.
- The properties and precautions of plastic screws  
→ P.xxxx
- Application

FPD production equipment / Semiconductor devices / Printed circuit board etching devices / Metallic surface treatment equipment and facilities / Chemical plants

Unit : mm

Part Number	M (Coarse)		B	T	Mass (g)
	Nominal of Thread	Pitch			
SPPVC-M3-N	M3	0.5	5.5	2.4	0.07
SPPVC-M4-N	M4	0.7	7	3.2	0.13
SPPVC-M5-N	M5	0.8	8	4	0.18
SPPVC-M6-N	M6	1	10	5	0.40
SPPVC-M8-N	M8	1.25	13	6.5	0.84
SPPVC-M10-N	M10	1.5	17	8	1.9
SPPVC-M12-N	M12	1.75	19	10	2.8

- Part number specification

## SPPVC-M5-N



Individual Sales → P.xxxx	Cleanroom Wash & Packaging → P.xxxx	Screw Length Adjustment → P.xxxx	Vibration Resistant → P.xxxx	Modification process for captive use → P.xxxx
1 piece in 1 pack	Available / Add'l charge	Not Available	Not Available	Not Available