




SNHS Hexagon Head Screws

SUS Stainless steel

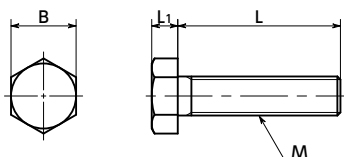

Material/Finish



	SNHS
Main Body	SUSXM7 (Equivalent to SUS304)
Strength Class	Equivalent to A2-50



- Stainless steel hexagon head screws compliant with JIS B 1180.

Unit : mm

Part Number 1	M (Coarse)		L 2												B	L1	Mass (g)	Qty per Pack
	Nominal of Thread	Pitch	6	8	10	12	16	20	25	30	35	40	45	50				
SNHS-M3	M3	0.5	6	8	10	12	16	20							5.5	2	0.65 - 1.3	20
SNHS-M4	M4	0.7	6	8	10	12	16	20	25	30					7	2.8	1.3 - 3.2	20
SNHS-M5	M5	0.8		8	10	12	16	20	25	30	35				8	3.5	2.5 - 5.8	20
SNHS-M6	M6	1			10	12	16	20	25	30	35	40			10	4	4.4 - 9.6	20
SNHS-M8	M8	1.25				12	16	20	25	30	35	40	45	50	13	5.5	10 - 22	10
SNHS-M10	M10	1.5					16	20	25	30	35	40	45	50	17	7	22 - 38	10

- When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

Part Number Specification

SNHS-M8-20

1

2

1 Individual Sales	2 Cleanroom Wash & Packaging	3 Screw Length Adjustment	4 Vibration Resistant	5 Modification process for captive use
Available / Add'l charge	Available / Add'l charge	Available / Add'l charge	Available / Add'l charge	Available / Add'l charge