




# SNS-J Socket Head Cap Screws

High strength High Specific Strength

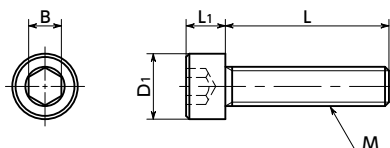

## Material/Finish



|                | <b>SNS-J</b>                             |
|----------------|------------------------------------------|
| Main Body      | SCM435<br>Ferroferric Oxide Film (Black) |
| Strength Class | 12.9                                     |



- Conforms to JIS B 1176, ISO 4762, and DIN 912.  
⇒ Technical Information : JIS B 1176, ISO 4762
- Strength class is 12.9. High strength.
- M3 - M16. Selection from abundant size variations is available to suit the device or equipment.

Unit : mm

| Part Number | M (Coarse)        |       | L |   |   |   |    |    |    |    |    |    |    |    |    |    |    |    | D1  | L1 | B   | Mass (g)   |          | Qty per Pack |
|-------------|-------------------|-------|---|---|---|---|----|----|----|----|----|----|----|----|----|----|----|----|-----|----|-----|------------|----------|--------------|
|             | Nominal of Thread | Pitch |   |   |   |   |    |    |    |    |    |    |    |    |    |    |    |    |     |    |     |            |          |              |
| SNS-M3      | M3                | 0.5   | 4 | 5 | 6 | 8 | 10 | 12 | 16 | 20 | 25 |    |    |    |    |    |    |    | 5.5 | 3  | 2.5 | 0.65 - 1.5 | 50       |              |
| SNS-M4      | M4                | 0.7   |   | 5 | 6 | 8 | 10 | 12 | 16 | 20 | 25 | 30 | 35 |    |    |    |    |    | 7   | 4  | 3   | 1.5 - 3.6  | 50       |              |
| SNS-M5      | M5                | 0.8   |   |   | 6 | 8 | 10 | 12 | 16 | 20 | 25 | 30 | 35 | 40 |    |    |    |    | 8.5 | 5  | 4   | 2.9 - 6.6  | 50       |              |
| SNS-M6      | M6                | 1     |   |   |   | 8 | 10 | 12 | 16 | 20 | 25 | 30 | 35 | 40 | 45 | 50 |    |    | 10  | 6  | 5   | 4.8 - 12   | 50       |              |
| SNS-M8      | M8                | 1.25  |   |   |   |   | 10 | 12 | 16 | 20 | 25 | 30 | 35 | 40 | 45 | 50 | 60 |    | 13  | 8  | 6   | 11 - 26    | 20       |              |
| SNS-M10     | M10               | 1.5   |   |   |   |   |    |    | 16 | 20 | 25 | 30 | 35 | 40 | 45 | 50 | 60 |    | 16  | 10 | 8   | 22 - 42    | 10       |              |
| SNS-M12     | M12               | 1.75  |   |   |   |   |    |    |    |    |    | 30 | 35 | 40 | 45 | 50 | 60 |    | 18  | 12 | 10  | 41 - 61    | 5        |              |
| SNS-M16     | M16               | 2     |   |   |   |   |    |    |    |    |    |    |    | 40 | 45 | 50 | 60 | 70 | 80  | 24 | 16  | 14         | 97 - 146 | 1            |

- When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

## Part Number Specification

### SNS-M5-12

1 2

|                          |                            |                          |                          |                                      |
|--------------------------|----------------------------|--------------------------|--------------------------|--------------------------------------|
| 1 Individual Sales       | Cleanroom Wash & Packaging | Screw Length Adjustment  | Vibration Resistant      | Modification process for captive use |
| Available / Add'l charge | Not Available              | Available / Add'l charge | Available / Add'l charge | Please feel free to contact us       |