




SEC-TBZ Super Ultra Low Profile Cross Recessed Machine Screws

Protrusion

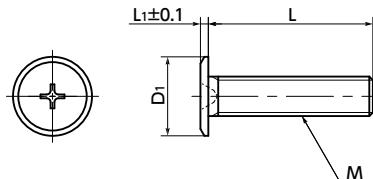

● Material/Finish

SEC-TBZ	
Main Body	Steel Black Trivalent Chromate Treatment



- Cross recessed head cap screws with extra low profile.
- For space-saving of equipment/devices and applications with limited overhead space.
- **SEC-TBZ**, with special cross recesses helping to prevent cam-out, are also available. The lineup includes some M3/M4 L dimensions.

● Application

Reducing the size of equipment and devices

Part Number	M (Coarse)		L	D1	L1	Cross-recessed Socket No.	Max. Tightening Torque*1 (N·m)	Mass (g)	Qty per Pack	Unit : mm
	Nominal of Thread	Pitch								
SEC-M2-TBZ	M2	0.4	2 3 4 5 6 8 10 12	4	0.5	0	0.14	0.05 - 0.23	50	
SEC-M2.5-TBZ	M2.5	0.45	3 4 5 6	5	0.6	1	0.35	0.13 - 0.23	50	
SEC-M2.6-TBZ	M2.6	0.45	3 4 5 6 8 10 12	5	0.6	1	0.35	0.13 - 0.44	50	
SEC-M3-TBZ	M3	0.5	3 4 5 6 8 10 12 16 20 22 25 30	6	0.8	1	0.35	0.15 - 1	50	
SEC-M4-TBZ	M4	0.7	4 5 6 8 10 12 16 20 22 25 30 35	8	0.9	2	0.91	0.33 - 2.2	50	
SEC-M5-TBZ	M5	0.8	8 10 12 16 20 22 25 30 35	9	1	2	1.19	1.5 - 3.7	50	
SEC-M6-TBZ	M6	1	8 10 12 16 20 22 25 30 35	10	1.2	2	2.94	2.5 - 6.5	20	

*1 : Values in chart are for reference only. They are not guaranteed values.

● When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

● Part Number Specification

SEC-M3-8-TBZ

1 2 1

1 Individual Sales Available / Add'l charge	2 Cleanroom Wash & Packaging Available / Add'l charge	3 Screw Length Adjustment Available / Add'l charge	4 Vibration Resistant Available / Add'l charge	5 Modification process for captive use Not Available
--	--	---	---	---