




SEC-TZB

Super Ultra Low Profile Cross Recessed Machine Screws

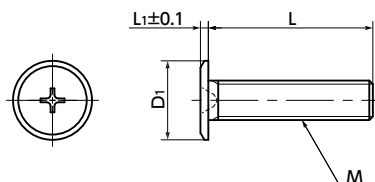

Material/Finish



	SEC-TZB
Main Body	Steel Trivalent Chromate Treatment



- Cross recessed head cap screws with extra low profile.
- For space-saving of equipment/devices and applications with limited overhead space.
- **SEC-TZB**, with special cross recesses helping to prevent cam-out, are also available. The lineup includes some M3/M4 L dimensions.

Application

Reducing the size of equipment and devices

Unit : mm																											
Part Number	M (Coarse)		L																D1	L1	Cross-recessed Socket No.	Max. Tightening Torque*1 (N・m)	Mass (g)	Qty per Pack			
	Nominal of Thread	Pitch																									
SEC-M2-TZB	M2	0.4	2	3	4	5	6	8	10	12									4	0.5	0	0.14	0.07 - 0.24	50			
SEC-M2.5-TZB	M2.5	0.45		3	4	5	6	8	10	12									5	0.6	1	0.38	0.14 - 0.41	50			
SEC-M2.6-TZB	M2.6	0.45		3	4	5	6	8	10	12	14								5	0.6	1	0.38	0.16 - 0.49	50			
SEC-M3-TZB	M3	0.5		3	4	5	6	8	10	12	14	15	16	20	22	25	30		6	0.8	1	0.42	0.3 - 1	50			
SEC-M4-TZB	M4	0.7			4	5	6	8	10	12	14	15	16	20	22	25	30	35	40	45	50	8	0.9	2	1.19	0.33 - 2.9	50
SEC-M5-TZB	M5	0.8				5	6	8	10	12	14	15	16	20	22	25	30	35	40	45	50	9	1	2	1.4	1.4 - 4.9	50
SEC-M6-TZB	M6	1					8	10	12	14	15	16	20	22	25	30	35	40	45	50	10	1.2	2	2.4	2.5 - 8	20	

*1: Values in chart are for reference only. They are not guaranteed values.

- When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

Part Number Specification

SEC-M3-8-TZB



1 Individual Sales	Cleanroom Wash & Packaging	Screw Length Adjustment	Vibration Resistant	Modification process for captive use
Available / Add'l charge	Available / Add'l charge	Available / Add'l charge	Available / Add'l charge	Not Available