




SHN-LP Thin Hex Nuts

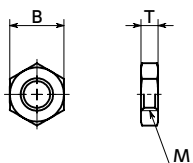

● Material/Finish



	SHN-LP
Main Body	Steel Trivalent Chromate Treatment

- Thin hex nuts conforming to ISO 4035.
- For space-saving of equipment/devices and applications with limited space.
- Application

Reducing the size of equipment and devices

Unit : mm

Part Number 	M (Coarse)		B	T	Mass (g)	Qty per Pack
	Nominal of Thread	Pitch				
SHN-M2-LP	M2	0.4	4	1.2	0.08	50
SHN-M2.5-LP	M2.5	0.45	5	1.6	0.17	50
SHN-M2.6-LP	M2.6	0.45	5	1.6	0.18	10
SHN-M3-LP	M3	0.5	5.5	1.8	0.21	50
SHN-M3.5-LP	M3.5	0.6	6	2	0.27	50
SHN-M4-LP	M4	0.7	7	2.2	0.47	50
SHN-M5-LP	M5	0.8	8	2.7	0.6	50
SHN-M6-LP	M6	1	10	3.2	1.3	50
SHN-M8-LP	M8	1.25	13	4	2.8	50
SHN-M10-LP	M10	1.5	17	5	6.3	20
SHN-M12-LP	M12	1.75	19	6	9.1	20
SHN-M14-LP	M14	2	22	7	13.5	10
SHN-M16-LP	M16	2	24	8	17.2	10

- When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

● Part Number Specification

SHN-M5-LP



Individual Sales	Cleanroom Wash & Packaging	Screw Length Adjustment	Vibration Resistant	Modification process for captive use
Available / Add'l charge	Available / Add'l charge	Not Available	Not Available	Not Available