


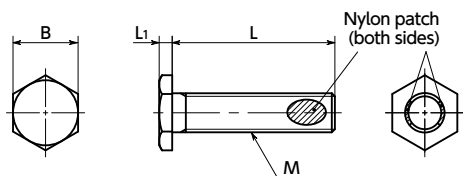

Vibration resistant treatment



Stainless steel



Material/Finish



RoHS


	SNHS-LH-ALK
Main Body	Equivalent to SUS304
Nylon Patch	Nylon 11

- Hex head bolts with special low profile and nylon patch.
- For space-saving of equipment/devices and applications with limited overhead space.
- The friction of the nylon adhered to the thread suppresses the return rotation of the thread.
- Even if the tightening force is lost, the return rotation is suppressed, preventing the screws from falling off.
- The heat resistant temperature of the nylon patch is 120°C.

Application

Reducing the size of equipment and devices
Screw return and fallout prevented

Unit : mm

Part Number 	M (Coarse)		L 							L1	B	Mass (g)	Qty per Pack
	Nominal of Thread	Pitch											
SNHS-M4-LH-ALK	M4	0.7	8	10	12	15	20	25	30	1.5	7	1.2 - 2.9	10
SNHS-M5-LH-ALK	M5	0.8	8	10	12	15	20	25	30	2	8	1.9 - 4.7	10
SNHS-M6-LH-ALK	M6	1		10	12	15	20	25	30	2	10	3.2 - 6.9	10
SNHS-M8-LH-ALK	M8	1.25				15	20	25	30	2	13	7.8 - 12	10

- When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

Part Number Specification

SNHS-M5-25-LH-ALK

Individual Sales	Cleanroom Wash & Packaging	Screw Length Adjustment	Vibration Resistant	Modification process for captive use
Available / Add'l charge	Available / Add'l charge	Not Available	Not Available	Not Available