




SNZF3S Cross Recessed Micro Flat Head Machine Screws - Type 0 - 3

Miniature Size **SUS** Stainless steel

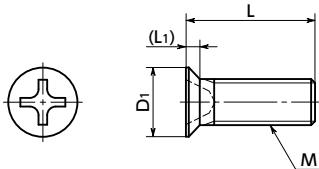

● Material/Finish

Main Body	SNZF3S	RoHS
	Stainless Steel	



- Miniature screws for precision instruments (Type 0 - 3).
- M1.4 - M2.
- Flat head machine screw type with low head height. For applications with limited overhead space.

● Application

For making devices and equipment more compact
Compact precision equipment

Part Number	M (Coarse) Nominal of Thread	Pitch	L										D1	L1	Cross-recessed Socket No.	Max. Tightening Torque (N·m)*1	Mass (g)	Qty per Pack	Unit : mm
			2	2.5	3	3.5	4	5	6	8	10	2.5							
SNZF3S-M1.4	M1.4	0.3	2	2.5	3	3.5	4	5	6	8	10	2.5	0.7	0	0.07	0.03 - 0.09	50		
SNZF3S-M1.6	M1.6	0.35	2	2.5	3		4	5	6	8	10	2.8	0.8	0	0.1	0.034 - 0.12	50		
SNZF3S-M1.7	M1.7	0.35		2.5	3	3.5	4	5	6	8	10	3	0.8	0	0.14	0.04 - 0.13	50		
SNZF3S-M2	M2	0.4			3		4	5	6	8	10	3.5	0.9	0	0.22	0.09 - 0.21	50		

*1 : Values in chart are for reference only. They are not guaranteed values.

● When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

● Part Number Specification

SNZF3S-M2-5

1

2

1 Individual Sales Available / Add'l charge	2 Cleanroom Wash & Packaging Available / Add'l charge	3 Screw Length Adjustment Not Available	4 Vibration Resistant Available / Add'l charge	5 Modification process for captive use Not Available
---	---	---	--	--