


SNSS-IG Self - Aligning Socket Head Cap Screws with Guide Tip



Seizing Prevention Easy operation SUS Stainless steel

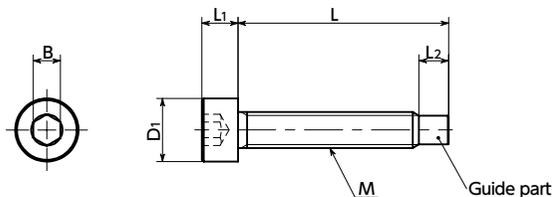

● Material/Finish




	SNSS-IG
Main Body	SUSXM7 (Equivalent to SUS304)
Strength Class	A2-70

⚠ Precautions for Use

- Be sure to tighten only after fully inserting the guide into the female screw. If not fully inserted, seizing may occur.
- Before use, check that there is no wear, cutting chips, etc., on the female screw part.
- Remaining screw threads may be visible on the guide part, but this does not affect function.

- Stainless steel hex socket head cap screws with guide.
- Structure with screw tip guide makes it easy to insert perpendicular to the female screw, even in locations where work is tricky.
- Prevents seizing and breakage due to diagonal tightening.

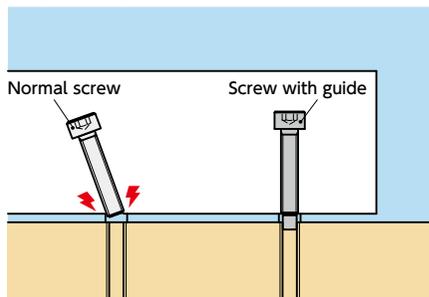

- Stable tightening is possible regardless of the worker's experience.
- Special surface treatment specifications are also available, further reducing seizing risks. Please contact our customer service.

● Application

For locations prone to diagonal screw tightening, such as narrow, high, or dark spaces
General industrial machines

Unit : mm

Part Number 1	M (Coarse)		L 2	D1	L1	B	L2	Mass (g)
	Nominal of Thread	Pitch						
SNSS-M3-IG	M3	0.5	8 10 12 16 20 25	5.5	3	2.5	2.4	0.8 - 1.6
SNSS-M4-IG	M4	0.7	10 12 16 20 25 30	7	4	3	3.3	1.8 - 3.7
SNSS-M5-IG	M5	0.8	12 16 20 25 30	8.5	5	4	3.8	3 - 5.6
SNSS-M6-IG	M6	1	16 20 25 30 35	10	6	5	4.7	5.8 - 9.9
SNSS-M8-IG	M8	1.25	20 25 30 35	13	8	6	5.9	13 - 19

● Part Number Specification



1 Individual Sales 1 piece in 1 pack	2 Cleanroom Wash & Packaging Available / Add'l charge	3 Screw Length Adjustment Not Available	4 Vibration Resistant Please feel free to contact us	5 Modification process for captive use Not Available
--	---	---	--	--