


## SNZF3-TBZ-ALK

Cross Recessed Micro Flat Head Machine Screws with Nylon Patch - Type 0-3



Vibration resistant treatment Miniature Size

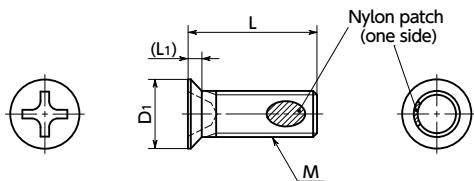

## ● Material/Finish

	SNZF3-TBZ-ALK	
Main Body	SWCH16A Black Trivalent Chromate Treatment	
Nylon Patch	Nylon 11	



- Miniature screws with nylon patch for precision instruments (Type 0-3).
- M1.4 - M2.6.
- The friction of the nylon adhered to the thread suppresses the return rotation of the thread.
- Even if the tightening force is lost, the return rotation is suppressed, preventing the screws from falling off.
- The heat resistant temperature of the nylon patch is 120°C.
- Flat head machine screw type with low head height. For applications with limited overhead space.

## ● Application

Screw return and fallout prevented  
For making devices and equipment more compact  
Compact precision equipment

Part Number	M (Coarse)		L	D1	L1	Cross-recessed Socket No.	Max. Tightening Torque (N·m)*1	Mass (g)	Qty per Pack	Unit : mm
	Nominal of Thread	Pitch								
SNZF3-M1.4-TBZ-ALK	M1.4	0.3	3 3.5 4 5 6	2.5	0.7	0	0.05	0.04 - 0.06	50	
SNZF3-M1.7-TBZ-ALK	M1.7	0.35	3 3.5 4 5 6	3	0.8	0	0.09	0.06 - 0.09	50	
SNZF3-M2-TBZ-ALK	M2	0.4	3 3.5 4 5 6 8	3.5	0.9	0	0.18	0.09 - 0.17	50	
SNZF3-M2.6-TBZ-ALK	M2.6	0.45	3.5 4 5 6	4.5	1.1	0	0.39	0.18 - 0.25	50	

\*1 : Values in chart are for reference only. They are not guaranteed values.

● When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

## ● Part Number Specification

SNZF3-M2-5-TBZ-ALK

Individual Sales Available / Add'l charge	Cleanroom Wash & Packaging Available / Add'l charge	Screw Length Adjustment Not Available	Vibration Resistant Not Available	Modification process for captive use Not Available
--	--	--	--------------------------------------	---