




SRHSET-ALK Hex Socket Set Screws (with Pin) with Nylon Patch

Vibration resistant treatment

Tamper Resistance

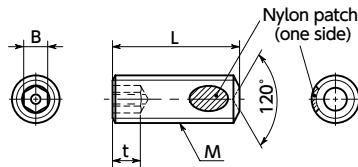

● Material/Finish



SRHSET-ALK

Main Body	Steel Ferrosferric Oxide Film (Black)
Nylon Patch	Nylon 11

● Application

Equipment/devices disassembly/tampering prevention
Theft prevention for outdoor facilities

Security measures
Safety measures

Screw return and fallout prevented



- Setscrews with a pin at the center of the hex socket.
- With nylon patch.
- The friction of the nylon adhered to the thread suppresses the return rotation of the thread.
- Even if the tightening force is lost, the return rotation is suppressed, preventing the screws from falling off.
- The heat resistant temperature of the nylon patch is 120°C.
- This prevents mounting and removing with regular tools.
- Install and remove with **SRH** Dedicated Wrench or **SRHB** Dedicated Bit and **SRD** Dedicated Magnetic Screwdriver together.

Unit : mm

Part Number	M (Coarse)	Nominal of Thread	Pitch	L	B	t min.	Applicable Wrench	Bit Part No.	Screwdriver Part No.	Mass (g)	Qty per Pack
SRHSET-M5-ALK	M5		0.8	8 10 12	2.5	2.5	SRH-3	SRHB-3	SRD-6.35	0.73 - 1.19	10
SRHSET-M6-ALK	M6		1	8 10 12 16	3.0	3	SRH-4	SRHB-4	SRD-6.35	0.98 - 2.3	10
SRHSET-M8-ALK	M8		1.25	10 12 16	4.0	4	SRH-5	SRHB-5	SRD-6.35	2.24 - 4.08	10

● When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

● Related Products

SRH dedicated wrenches are available.



SRHB applicable bits are available.



Dedicated magnetic screwdrivers **SRD** are available.



● Part Number Specification

SRHSET-M5-12-ALK

1

2

1

1 Individual Sales

Available / Add'l charge

Cleanroom Wash & Packaging

Not Available

Screw Length Adjustment

Not Available

Vibration Resistant

Not Available

Modification process for captive use

Not Available