




SRHSET

Hex Socket Set Screws (with Pin)

Tamper Resistance

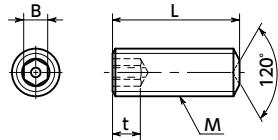

● Material/Finish

	SRHSET	RoHS
Main Body	Steel Ferrosferric Oxide Film (Black)	



- Setscrews with a pin at the center of the hex socket.
- This prevents mounting and removing with regular tools.
- Install and remove with **SRH** Dedicated Wrench or **SRHB** Dedicated Bit and **SRD** Dedicated Magnetic Screwdriver together.

● Application

Equipment/devices disassembly/tampering prevention
Theft prevention for outdoor facilities
Security measures
Safety measures

Part Number	Unit : mm												
	M (Coarse)		L	B	t min.	Applicable Wrench	Bit Part No.	Screwdriver Part No.	Mass (g)	Qty per Pack			
	Nominal of Thread	Pitch											
SRHSET-M5	M5	0.8	8	10	12	2.5	3	SRH-3	SRHB-3	SRD-6.35	0.73 - 1.19	10	
SRHSET-M6	M6	1	8	10	12	16	3.0	3.5	SRH-4	SRHB-4	SRD-6.35	0.98 - 2.3	10
SRHSET-M8	M8	1.25	10	12	16	4.0	5	SRH-5	SRHB-5	SRD-6.35	2.24 - 4.08	10	

● When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

● Related Products

SRH dedicated wrenches are available.



SRHB applicable bits are available.



Dedicated magnetic screwdrivers **SRD** are available.



● Part Number Specification

SRHSET-M5-12

1

2

1 Individual Sales
Available / Add'l charge

Cleanroom Wash & Packaging
Not Available

Screw Length Adjustment
Not Available

Vibration Resistant
Available / Add'l charge

Modification process for captive use
Not Available