




# SRP-TZB-ALK Cross Recessed (with Pin) Pan Head Machine Screws with Nylon Patch

Vibration resistant treatment

Tamper Resistance

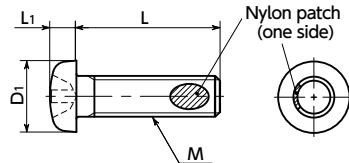

## ● Material/Finish



	SRP-TZB-ALK
Main Body	Steel Trivalent Chromate
Nylon Patch	Nylon 11
Strength Class	4.8 Equivalent

## ● Application

Equipment/devices disassembly/tampering prevention

Theft prevention for outdoor facilities

Security measures

Safety measures

Screw return and fallout prevented



- Pan head machine screws with a pin at the center of the cross recess.
- With nylon patch.
- The friction of the nylon adhered to the thread suppresses the return rotation of the thread.
- Even if the tightening force is lost, the return rotation is suppressed, preventing the screws from falling off.
- The heat resistant temperature of the nylon patch is 120°C.
- This prevents mounting and removing with regular tools.
- Install and remove with **SRCB** dedicated bits and **SRD** dedicated magnetic screwdriver in combination.

Unit : mm

Part Number  1	M (Coarse)		L  2	D1	L1	Cross-recessed Socket No.	Bit Part No.	Screwdriver Part No.	Mass (g)	Qty per Pack
	Nominal of Thread	Pitch								
<b>SRP-M3-TZB-ALK</b>	M3	0.5	6 8 10	5.5	2	2	SRCB-2	SRD-6.35	0.45 - 0.62	20
<b>SRP-M4-TZB-ALK</b>	M4	0.7	6 10 16	7	2.6	2	SRCB-2	SRD-6.35	0.97 - 1.67	20
<b>SRP-M5-TZB-ALK</b>	M5	0.8	10 16 20	9	3.3	2	SRCB-2	SRD-6.35	2.25 - 3.43	20
<b>SRP-M6-TZB-ALK</b>	M6	1	10 16 20	10.5	3.9	3	SRCB-3	SRD-6.35	3.5 - 5	20

● When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

## ● Related Products

**SRCB** applicable bits are available.



Dedicated magnetic screwdrivers **SRD** are available.



## ● Part Number Specification

**SRP-M5-16-TZB-ALK**



Individual Sales

Available / Add'l charge

Cleanroom Wash & Packaging

Available / Add'l charge

Screw Length Adjustment

Not Available

Vibration Resistant

Not Available

Modification process for captive use

Not Available