




SRTFS Two - Hole Flat Head Machine Screws

Tamper Resistance

SUS Stainless steel

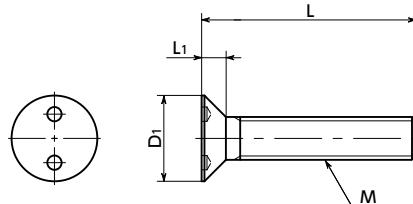

● Material/Finish



SRTFS

Main Body	Equivalent to SUS304
Strength Class	Equivalent to A2-50



- Two-hole flat head machine screws.
- This prevents mounting and removing with regular tools.
- Install and remove with **SRTB** Dedicated Bits and **SRD** Dedicated Magnetic Screwdriver together.
- The simple head design is also suitable for decoration.

● Application

Equipment/devices disassembly/tampering prevention

Theft prevention for outdoor facilities

Security measures

Safety measures

Part Number	M (Coarse)										D1	L1	Bit Part No.	Screwdriver Part No.	Mass (g)	Qty per Pack	Unit : mm	
	Nominal of Thread	Pitch	L															
SRTFS-M3	M3	0.5	6	8	10	12	16		30		5.6	1.65	SRTB-4	SRD-6.35	0.35 - 1.34	10		
SRTFS-M4	M4	0.7			10	12	16	20	25	35	7.5	2.2	SRTB-8	SRD-6.35	1.03 - 2.82	10		
SRTFS-M5	M5	0.8				12	16	20	25	30	35	9.2	2.5	SRTB-10	SRD-6.35	1.88 - 4.58	10	
SRTFS-M6	M6	1.0				12	16	20	25	30	40	11	3	SRTB-14	SRD-6.35	2.9 - 8.01	10	

● When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

● Related Products

Washer for Flat Head Screw

SWAS-RW is available.

SRTB applicable bits are available.



Dedicated magnetic screwdrivers **SRD** are available.



● Part Number Specification

SRTFS-M5 - 16

1

2

1 Individual Sales

Available / Add'l charge

2 Cleanroom Wash & Packaging

Available / Add'l charge

3 Screw Length Adjustment

Available / Add'l charge

4 Vibration Resistant

Available / Add'l charge

5 Modification process for captive use

Not Available