




# SRTSQ-TZB-ALK

## Hexalobular Socket (with Pin) Pan Head Machine Screws with Washer with Nylon Patch

Vibration resistant treatment Tamper Resistance Easy operation

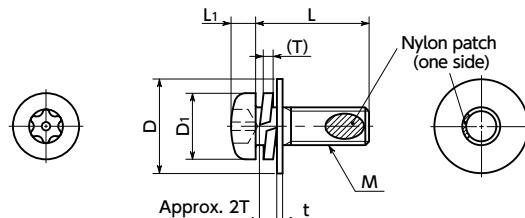

### ● Material/Finish

	SRTSQ-TZB-ALK	RoHS
Screw Body	Steel Trivalent Chromate Treatment	
Screw Body Strength Class	4.8 Equivalent	
Plain Washer	Steel Trivalent Chromate Treatment	
Spring Washer	Steel Trivalent Chromate Treatment	
Nylon Patch	Nylon 11	

- Pan head machine screws with captive washers, with a pin at the center of the hexalobular socket\*1.
- With nylon patch.
- Former JIS-standard plain washers and spring washers are integrated into the screws, preventing concerns about fallout issues. (Washer abbreviation: I=3)
- For screws with captive washers, see "What are screws with captive washers (SEMS screws)?" .
- When using a washer in spot facing, workability is improved because the bolt and washer can be mounted and removed at the same time.
- The friction of the nylon adhered to the thread suppresses the return rotation of the thread.
- Even if the tightening force is lost, the return rotation is suppressed, preventing the screws from falling off.
- The heat resistant temperature of the nylon patch is 120°C.
- This prevents mounting and removing with regular tools.
- Install and remove with **SRX** Dedicated Wrench or **SRXB** Dedicated Bit and **SRD** Dedicated Magnetic Screwdriver together.

\*1: The hexalobular shape is prescribed by JIS B 1015: 2008(ISO 10664: 2005)"Hexalobular internal driving feature for bolts and screws".

### ● Application

Equipment/devices disassembly/tampering prevention  
Theft prevention for outdoor facilities  
Security measures  
Safety measures  
Screw return and fallout prevented

Part Number  1	M (Coarse)		L  2	D1	D	L1	t	T (Approx.)	Applicable Wrench	Bit Part No.	Screwdriver Part No.	Hexalobular Socket No.	Mass (g)	Qty per Pack	Unit : mm	
	Nominal of Thread	Pitch														
<b>SRTSQ-M2-TZB-ALK</b>	M2	0.4	5	6	8		3.5	5	1.3	0.3	0.7	—	SRXB-6	SRD-6.35	6	0.24 - 0.27 20
<b>SRTSQ-M2.6-TZB-ALK</b>	M2.6	0.45	5	6	8		4.5	6.5	1.7	0.5	0.7	—	SRXB-8	SRD-6.35	8	0.45 - 0.57 20
<b>SRTSQ-M3-TZB-ALK</b>	M3	0.5	6	8	10		5.5	7	2	0.5	0.7	SRX-10	SRXB-10	SRD-6.35	10	0.68 - 0.87 20
<b>SRTSQ-M4-TZB-ALK</b>	M4	0.7	8	10	12	7	9	2.6	0.8	1	SRX-20	SRXB-20	SRD-6.35	20	1.61 - 1.92 20	

● When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

### ● Related Products

**SRX** dedicated wrenches are available.



**SRXB** applicable bits are available.



Dedicated magnetic screwdrivers **SRD** are available.



### ● Part Number Specification

**SRTSQ-M3-10-TZB-ALK**

1 2 1

Individual Sales	Cleanroom Wash & Packaging	Screw Length Adjustment	Vibration Resistant	Modification process for captive use
Available / Add'l charge	Available / Add'l charge	Not Available	Not Available	Not Available