

## ● 材質・仕上げ



SBSM	
本体	スチール 四三酸化鉄皮膜(黒)
強度区分	12.9




- 位置決めや、対象物の保持などの用途に適した精密ボルトです。

単位: mm

品番	M(並目)		D <sub>2</sub>	L <sub>2</sub>	L	D	L <sub>1</sub>	B	質量(g)
	ねじの呼び	ピッチ							
SBSM-M3-4-4	M3	0.5	4	4	7	7	3	2	1.5
SBSM-M3-4-5	M3	0.5	4	5	7	7	3	2	2
SBSM-M3-4-6	M3	0.5	4	6	7	7	3	2	2
SBSM-M3-4-8	M3	0.5	4	8	7	7	3	2	2
SBSM-M3-4-10	M3	0.5	4	10	7	7	3	2	2
SBSM-M3-4-12	M3	0.5	4	12	7	7	3	2	2
SBSM-M3-4-16	M3	0.5	4	16	7	7	3	2	2
SBSM-M3-4-20	M3	0.5	4	20	7	7	3	2	3
SBSM-M3-4-25	M3	0.5	4	25	7	7	3	2	3.5
SBSM-M3-4-30	M3	0.5	4	30	7	7	3	2	4
SBSM-M4-5-5	M4	0.7	5	5	8	9	4	2.5	2.9
SBSM-M4-5-6	M4	0.7	5	6	8	9	4	2.5	3.2
SBSM-M4-5-8	M4	0.7	5	8	8	9	4	2.5	3.4
SBSM-M4-5-10	M4	0.7	5	10	8	9	4	2.5	4
SBSM-M4-5-12	M4	0.7	5	12	8	9	4	2.5	4
SBSM-M4-5-16	M4	0.7	5	16	8	9	4	2.5	4
SBSM-M4-5-20	M4	0.7	5	20	8	9	4	2.5	5.3
SBSM-M4-5-25	M4	0.7	5	25	8	9	4	2.5	6.9
SBSM-M4-5-30	M4	0.7	5	30	8	9	4	2.5	7
SBSM-M4-5-40	M4	0.7	5	40	8	9	4	2.5	9
SBSM-M5-6-10	M5	0.8	6	10	9.5	10	4.5	3	5.8
SBSM-M5-6-12	M5	0.8	6	12	9.5	10	4.5	3	6.2
SBSM-M5-6-16	M5	0.8	6	16	9.5	10	4.5	3	7
SBSM-M5-6-20	M5	0.8	6	20	9.5	10	4.5	3	7.9
SBSM-M5-6-25	M5	0.8	6	25	9.5	10	4.5	3	8.5
SBSM-M5-6-30	M5	0.8	6	30	9.5	10	4.5	3	10
SBSM-M5-6-35	M5	0.8	6	35	9.5	10	4.5	3	10
SBSM-M5-6-40	M5	0.8	6	40	9.5	10	4.5	3	12.4
SBSM-M5-6-45	M5	0.8	6	45	9.5	10	4.5	3	14.2
SBSM-M5-6-50	M5	0.8	6	50	9.5	10	4.5	3	15
SBSM-M5-6-55	M5	0.8	6	55	9.5	10	4.5	3	15
SBSM-M5-6-60	M5	0.8	6	60	9.5	10	4.5	3	16.5
SBSM-M5-6-65	M5	0.8	6	65	9.5	10	4.5	3	17.6
SBSM-M5-6-70	M5	0.8	6	70	9.5	10	4.5	3	18.8
SBSM-M5-6-80	M5	0.8	6	80	9.5	10	4.5	3	20.9

## ● 使用例

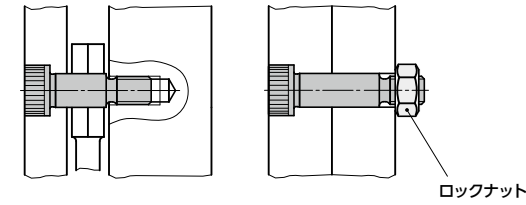

単位: mm

品番	M(並目)		D <sub>2</sub>	L <sub>2</sub>	L	D	L <sub>1</sub>	B	質量(g)
	ねじの呼び	ピッチ							
SBSM-M6-8-16	M6	1	8	16	11	13	5.5	4	13
SBSM-M6-8-20	M6	1	8	20	11	13	5.5	4	15
SBSM-M6-8-25	M6	1	8	25	11	13	5.5	4	16.6
SBSM-M6-8-30	M6	1	8	30	11	13	5.5	4	18
SBSM-M6-8-35	M6	1	8	35	11	13	5.5	4	19
SBSM-M6-8-40	M6	1	8	40	11	13	5.5	4	23
SBSM-M6-8-45	M6	1	8	45	11	13	5.5	4	25
SBSM-M6-8-50	M6	1	8	50	11	13	5.5	4	26
SBSM-M6-8-55	M6	1	8	55	11	13	5.5	4	28
SBSM-M6-8-60	M6	1	8	60	11	13	5.5	4	30
SBSM-M6-8-65	M6	1	8	65	11	13	5.5	4	32
SBSM-M6-8-70	M6	1	8	70	11	13	5.5	4	34
SBSM-M6-8-80	M6	1	8	80	11	13	5.5	4	38
SBSM-M6-8-90	M6	1	8	90	11	13	5.5	4	42
SBSM-M6-8-100	M6	1	8	100	11	13	5.5	4	46
SBSM-M8-10-16	M8	1.25	10	16	13	16	7	5	23
SBSM-M8-10-20	M8	1.25	10	20	13	16	7	5	25
SBSM-M8-10-25	M8	1.25	10	25	13	16	7	5	29
SBSM-M8-10-30	M8	1.25	10	30	13	16	7	5	31.8
SBSM-M8-10-35	M8	1.25	10	35	13	16	7	5	34.6
SBSM-M8-10-40	M8	1.25	10	40	13	16	7	5	38
SBSM-M8-10-45	M8	1.25	10	45	13	16	7	5	41
SBSM-M8-10-50	M8	1.25	10	50	13	16	7	5	43
SBSM-M8-10-55	M8	1.25	10	55	13	16	7	5	47
SBSM-M8-10-60	M8	1.25	10	60	13	16	7	5	50
SBSM-M8-10-65	M8	1.25	10	65	13	16	7	5	53
SBSM-M8-10-70	M8	1.25	10	70	13	16	7	5	56
SBSM-M8-10-80	M8	1.25	10	80	13	16	7	5	62
SBSM-M8-10-90	M8	1.25	10	90	13	16	7	5	68
SBSM-M8-10-100	M8	1.25	10	100	13	16	7	5	75


- 品番指定 ※価格・納期はNBKウェブサイトをご覧ください。

SBSM-M5-6-25



クリーン洗浄・クリーン梱包 対応不可	ねじ組み合わせ 対応不可	ねじカット 対応不可	ゆるみ止め 対応可・別料金
-----------------------	-----------------	---------------	------------------

単位 : mm

品番 	M(並目)		D <sub>2</sub>	L <sub>2</sub>	L	D	L <sub>1</sub>	B	質量 (g)
	ねじの呼び	ピッチ							
SBSM-M10-12-16	M10	1.5	12	16	16	18	9-1	6	30
SBSM-M10-12-20	M10	1.5	12	20	16	18	9-1	6	39
SBSM-M10-12-25	M10	1.5	12	25	16	18	9-1	6	43
SBSM-M10-12-30	M10	1.5	12	30	16	18	9-1	6	50
SBSM-M10-12-35	M10	1.5	12	35	16	18	9-1	6	52
SBSM-M10-12-40	M10	1.5	12	40	16	18	9-1	6	58
SBSM-M10-12-45	M10	1.5	12	45	16	18	9-1	6	60
SBSM-M10-12-50	M10	1.5	12	50	16	18	9-1	6	65
SBSM-M10-12-55	M10	1.5	12	55	16	18	9-1	6	71
SBSM-M10-12-60	M10	1.5	12	60	16	18	9-1	6	73
SBSM-M10-12-65	M10	1.5	12	65	16	18	9-1	6	75
SBSM-M10-12-70	M10	1.5	12	70	16	18	9-1	6	82.7
SBSM-M10-12-80	M10	1.5	12	80	16	18	9-1	6	91
SBSM-M10-12-90	M10	1.5	12	90	16	18	9-1	6	96
SBSM-M10-12-100	M10	1.5	12	100	16	18	9-1	6	100
SBSM-M12-16-25	M12	1.75	16	25	18	24	11	8	85
SBSM-M12-16-30	M12	1.75	16	30	18	24	11	8	94
SBSM-M12-16-35	M12	1.75	16	35	18	24	11	8	100
SBSM-M12-16-40	M12	1.75	16	40	18	24	11	8	108
SBSM-M12-16-45	M12	1.75	16	45	18	24	11	8	118
SBSM-M12-16-50	M12	1.75	16	50	18	24	11	8	126
SBSM-M12-16-55	M12	1.75	16	55	18	24	11	8	131
SBSM-M12-16-60	M12	1.75	16	60	18	24	11	8	140
SBSM-M12-16-65	M12	1.75	16	65	18	24	11	8	148
SBSM-M12-16-70	M12	1.75	16	70	18	24	11	8	155
SBSM-M12-16-80	M12	1.75	16	80	18	24	11	8	160
SBSM-M12-16-90	M12	1.75	16	90	18	24	11	8	186
SBSM-M12-16-100	M12	1.75	16	100	18	24	11	8	200
SBSM-M16-20-30	M16	2	20	30	22	30	14	10	168.5
SBSM-M16-20-35	M16	2	20	35	22	30	14	10	170
SBSM-M16-20-40	M16	2	20	40	22	30	14	10	195
SBSM-M16-20-45	M16	2	20	45	22	30	14	10	205
SBSM-M16-20-50	M16	2	20	50	22	30	14	10	220
SBSM-M16-20-55	M16	2	20	55	22	30	14	10	230
SBSM-M16-20-60	M16	2	20	60	22	30	14	10	244
SBSM-M16-20-65	M16	2	20	65	22	30	14	10	260
SBSM-M16-20-70	M16	2	20	70	22	30	14	10	266
SBSM-M16-20-80	M16	2	20	80	22	30	14	10	290
SBSM-M16-20-90	M16	2	20	90	22	30	14	10	315
SBSM-M16-20-100	M16	2	20	100	22	30	14	10	339.5
SBSM-M20-24-50	M20	2.5	24	50	27	36	16	12	339.8
SBSM-M20-24-55	M20	2.5	24	55	27	36	16	12	360
SBSM-M20-24-60	M20	2.5	24	60	27	36	16	12	370
SBSM-M20-24-65	M20	2.5	24	65	27	36	16	12	393
SBSM-M20-24-70	M20	2.5	24	70	27	36	16	12	409.8
SBSM-M20-24-80	M20	2.5	24	80	27	36	16	12	450
SBSM-M20-24-90	M20	2.5	24	90	27	36	16	12	480
SBSM-M20-24-100	M20	2.5	24	100	27	36	16	12	515.9