

● 材質・仕上げ



	SBSMS
本体	SUS304相当




- 位置決めや、対象物の保持などの用途に適した精密ボルトです。
- 耐蝕性にすぐれたステンレス製。

単位：mm

品番	M(並目)		D ₂	L ₂	L	D	L ₁	B	質量(g)
	ねじの呼び	ピッチ							
SBSMS-M3-4-4	M3	0.5	4	4	7	7	3	2	1.5
SBSMS-M3-4-5	M3	0.5	4	5	7	7	3	2	1.5
SBSMS-M3-4-6	M3	0.5	4	6	7	7	3	2	1.6
SBSMS-M3-4-8	M3	0.5	4	8	7	7	3	2	1.8
SBSMS-M3-4-10	M3	0.5	4	10	7	7	3	2	2
SBSMS-M3-4-12	M3	0.5	4	12	7	7	3	2	2
SBSMS-M3-4-16	M3	0.5	4	16	7	7	3	2	3
SBSMS-M4-5-5	M4	0.7	5	5	8	9	4	2.5	3
SBSMS-M4-5-6	M4	0.7	5	6	8	9	4	2.5	3
SBSMS-M4-5-8	M4	0.7	5	8	8	9	4	2.5	3
SBSMS-M4-5-10	M4	0.7	5	10	8	9	4	2.5	3
SBSMS-M4-5-12	M4	0.7	5	12	8	9	4	2.5	4
SBSMS-M4-5-16	M4	0.7	5	16	8	9	4	2.5	4.5
SBSMS-M4-5-20	M4	0.7	5	20	8	9	4	2.5	5.3
SBSMS-M4-5-25	M4	0.7	5	25	8	9	4	2.5	6
SBSMS-M4-5-30	M4	0.7	5	30	8	9	4	2.5	7
SBSMS-M5-6-10	M5	0.8	6	10	9.5	10	4.5	3	6
SBSMS-M5-6-12	M5	0.8	6	12	9.5	10	4.5	3	6
SBSMS-M5-6-16	M5	0.8	6	16	9.5	10	4.5	3	7
SBSMS-M5-6-20	M5	0.8	6	20	9.5	10	4.5	3	8
SBSMS-M5-6-25	M5	0.8	6	25	9.5	10	4.5	3	10
SBSMS-M5-6-30	M5	0.8	6	30	9.5	10	4.5	3	10
SBSMS-M5-6-40	M5	0.8	6	40	9.5	10	4.5	3	12
SBSMS-M5-6-50	M5	0.8	6	50	9.5	10	4.5	3	14
SBSMS-M5-6-60	M5	0.8	6	60	9.5	10	4.5	3	14
SBSMS-M6-8-16	M6	1	8	16	11	13	5.5	4	13.1
SBSMS-M6-8-20	M6	1	8	20	11	13	5.5	4	14.4
SBSMS-M6-8-25	M6	1	8	25	11	13	5.5	4	17
SBSMS-M6-8-30	M6	1	8	30	11	13	5.5	4	18
SBSMS-M6-8-40	M6	1	8	40	11	13	5.5	4	21
SBSMS-M6-8-50	M6	1	8	50	11	13	5.5	4	25.5
SBSMS-M6-8-60	M6	1	8	60	11	13	5.5	4	30.5

● 使用例

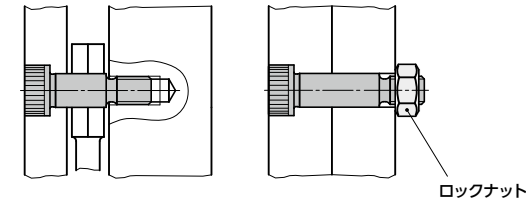

単位：mm

品番	M(並目)		D ₂	L ₂	L	D	L ₁	B	質量(g)
	ねじの呼び	ピッチ							
SBSMS-M8-10-16	M8	1.25	10	16	13	16	7	5	23
SBSMS-M8-10-20	M8	1.25	10	20	13	16	7	5	25
SBSMS-M8-10-25	M8	1.25	10	25	13	16	7	5	29
SBSMS-M8-10-30	M8	1.25	10	30	13	16	7	5	32
SBSMS-M8-10-40	M8	1.25	10	40	13	16	7	5	40
SBSMS-M8-10-50	M8	1.25	10	50	13	16	7	5	45
SBSMS-M8-10-60	M8	1.25	10	60	13	16	7	5	50
SBSMS-M8-10-70	M8	1.25	10	70	13	16	7	5	56
SBSMS-M8-10-80	M8	1.25	10	80	13	16	7	5	62
SBSMS-M8-10-90	M8	1.25	10	90	13	16	7	5	68
SBSMS-M8-10-100	M8	1.25	10	100	13	16	7	5	75
SBSMS-M10-12-16	M10	1.5	12	16	16	18	9	6	35
SBSMS-M10-12-20	M10	1.5	12	20	16	18	9	6	39
SBSMS-M10-12-25	M10	1.5	12	25	16	18	9	6	45
SBSMS-M10-12-30	M10	1.5	12	30	16	18	9	6	47
SBSMS-M10-12-40	M10	1.5	12	40	16	18	9	6	56
SBSMS-M10-12-50	M10	1.5	12	50	16	18	9	6	65
SBSMS-M10-12-60	M10	1.5	12	60	16	18	9	6	76
SBSMS-M10-12-70	M10	1.5	12	70	16	18	9	6	86
SBSMS-M10-12-80	M10	1.5	12	80	16	18	9	6	91
SBSMS-M10-12-90	M10	1.5	12	90	16	18	9	6	99
SBSMS-M10-12-100	M10	1.5	12	100	16	18	9	6	100
SBSMS-M12-16-30	M12	1.75	16	30	18	24	11	8	92.8
SBSMS-M12-16-40	M12	1.75	16	40	18	24	11	8	108.7
SBSMS-M12-16-50	M12	1.75	16	50	18	24	11	8	123
SBSMS-M12-16-60	M12	1.75	16	60	18	24	11	8	123
SBSMS-M12-16-70	M12	1.75	16	70	18	24	11	8	155
SBSMS-M12-16-80	M12	1.75	16	80	18	24	11	8	170
SBSMS-M12-16-90	M12	1.75	16	90	18	24	11	8	186
SBSMS-M12-16-100	M12	1.75	16	100	18	24	11	8	200

● 品番指定 ※価格・納期はNBKウェブサイトをご覧ください。

SBSMS-M5-6-25

クリーン洗浄・クリーン梱包 お問い合わせください	ねじ組み合わせ 対応不可	ねじカット 対応不可	ゆるみ止め 対応可・別料金
-----------------------------	-----------------	---------------	------------------