
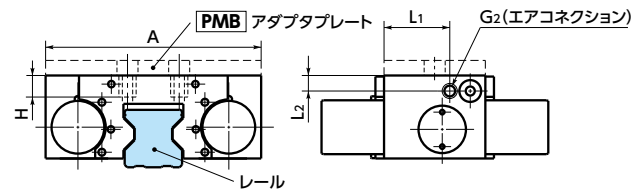


MBPS リニアクランプ・ズィー - 空気圧 - 常時閉 - ブレーキ機構つき

空気圧タイプ プレーキ機構つき N/C 常時閉

レールの呼び#15~#45

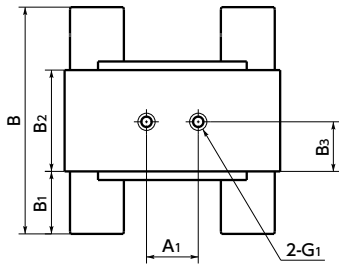



●クランプ部の形状は品番により異なります。各品番の形状は、CADデータをご確認ください。

寸法・性能

単位:mm

品番	保持力 (N)	A	A1	B	B1	B2	B3	G1	G2	L1	L2	H	質量 (kg)
MBPS-1501-AS1	800	61	15	94	19	44	22	M5	M5	34.5	5.3	7.3	0.52
MBPS-1501-ES1	900	61	15	94	19	44	22	M5	M5	34.5	5.3	8.6	0.42
MBPS-1504-BS1	800	61	15	94	19	44	22	M5	M5	34.5	5.3	7.3	0.43
MBPS-1505-AS1	900	61	15	94	19	44	22	M5	M5	34.5	5.3	7.3	0.43
MBPS-1512-ES1	800	61	15	94	19	44	22	M5	M5	34.5	5.3	7.3	0.42
MBPS-1514-DS1	900	61	15	94	19	44	22	M5	M5	34.5	5.3	7.3	0.44
MBPS-2001-AS1	900	66	20	94	19	44	22	M6	M5	15.5	5.5	8.6	0.77
MBPS-2001-CS1	900	66	20	94	19	44	22	M6	M5	15.5	5.5	8.6	0.52
MBPS-2001-ES1	1000	66	20	94	19	44	22	M6	M5	15.5	5.5	8.6	0.49
MBPS-2001-GS1	1000	66	20	94	19	44	22	M6	M5	15.5	5.5	8.6	0.49
MBPS-2002-AS1	900	66	20	94	19	44	22	M6	M5	15.5	5.5	8.6	0.49
MBPS-2002-BS1	900	66	20	94	19	44	22	M6	M5	15.5	5.5	8.6	0.49
MBPS-2004-BS1	900	66	20	94	19	44	22	M6	M5	15.5	5.5	8.6	0.49
MBPS-2005-AS1	1000	66	20	94	19	44	22	M6	M5	15.5	5.5	8.6	0.51
MBPS-2010-BS1	1000	66	20	94	19	44	22	M6	M5	15.5	5.5	8.6	0.49
MBPS-2012-FS1	1000	66	20	94	19	44	22	M6	M5	15.5	5.5	8.6	0.5

レールの呼び#55

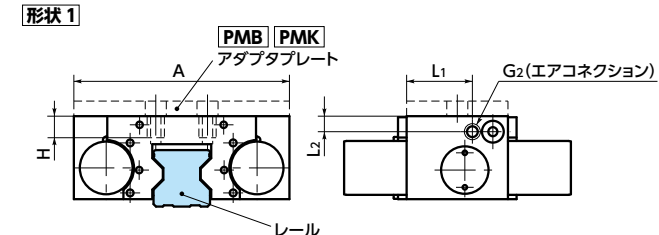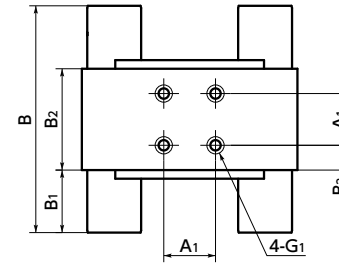

●クランプ部の形状は品番により異なります。各品番の形状は、CADデータをご確認ください。

単位:mm

品番	保持力 (N)	A	A1	B	B1	B2	B3	G1	G2	L1	L2	H	質量 (kg)
MBPS-2501-ES1	1300	75	20	95.2	20.2	44	22	M6	M5	16.5	6.5	8	0.78
MBPS-2501-GS1	1000	75	20	95	22	44	22	M6	M5	33	6	8	0.59
MBPS-2501-IS1	750	72	20	94	19	44	22	M6	M5	35.2	8.2	8.6	0.58
MBPS-2502-AS1	1200	75	20	94	22	44	22	M6	M5	16.2	5	8	0.64
MBPS-2502-BS1	850	75	20	94	22	44	22	M6	M5	16.2	5	7	0.63
MBPS-2502-DS1	750	75	20	94	22	44	22	M6	M5	16.2	5	7	0.63
MBPS-2503-AS1	1300	75	20	95.2	20.2	44	22	M6	M5	16.5	6.5	8	0.77
MBPS-2504-BS1	1200	75	20	94	22	44	22	M6	M5	16.2	5	8	0.65
MBPS-2504-FS1	1300	75	20	95.2	20.2	44	22	M6	M5	16.5	6.5	8	0.78
MBPS-2505-AS1	1300	75	20	95.2	20.2	44	22	M6	M5	16.5	6.5	8	0.77
MBPS-2505-BS1	1300	75	20	95.2	20.2	44	22	M6	M5	16.5	6.5	8	0.78
MBPS-2510-AS1	1000	75	20	94	22	44	22	M6	M5	16.2	5	8	0.62
MBPS-2514-DS1	1300	75	20	95.2	20.2	44	22	M6	M5	16.5	6.5	8	0.78
MBPS-3001-ES1	1300	90	22	98.2	20.2	47	23	M8	M5	14	6.5	9	0.98
MBPS-3002-AS1	1300	90	22	98.2	20.2	47	23	M8	M5	14	6.5	9	0.99
MBPS-3002-BS1	2000	90	22	107	29	47	23	M8	M5	30.5	7.2	9	1.14
MBPS-3004-BS1	1300	90	22	98.2	20.2	47	23	M8	M5	14	6.5	9	1.03
MBPS-3004-FS1	2000	90	22	107	29	47	23	M8	M5	30.5	7.2	9	1.15
MBPS-3005-AS1	2000	90	22	107	29	47	23	M8	M5	30.5	7.2	9	1.15
MBPS-3010-BS1	1300	90	22	98.2	20.2	47	23	M8	M5	14	6.5	9	1
MBPS-3012-FS1	2000	90	22	107	29	47	23	M8	M5	30.5	7.2	9	1.15
MBPS-3014-ES1	1300	90	22	98.2	20.2	47	23	M8	M5	14	6.5	9	1.2

●品番指定 ※価格・納期はNBKウェブサイトをご覧ください。

MBPS-2501-ES1





レバー位置変更

対応不可

MBPS リニアクランプ・ズィー - 空気圧 - 常時閉 - ブレーキ機構つき

空気圧タイプ プレーキ機構つき N/C 常時閉

レールの呼び#15~#45

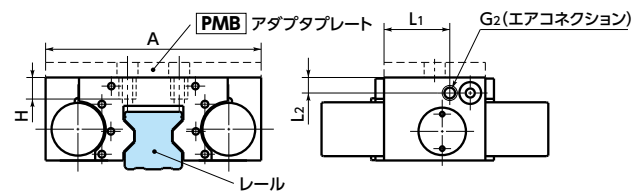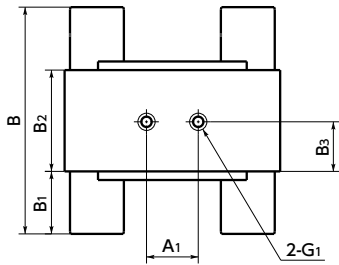



●クランプ部の形状は品番により異なります。各品番の形状は、CADデータをご確認ください。

寸法・性能

単位:mm

品番	保持力 (N)	A	A1	B	B1	B2	B3	G1	G2	L1	L2	H	質量 (kg)
MBPS-3501-AS1-A	2000	100	24	106	29	48	24.5	M8	M5	19	7.5	9	1.24
MBPS-3501-CS1-A	2000	100	24	106	29	48	24.5	M8	M5	19	7.5	9	1.28
MBPS-3501-ES1	2600	100	24	105.7	27.7	46	24.5	M8	G1/8	19	9	10	1.29
MBPS-3501-FS1-A	2000	100	24	106	29	48	24.5	M8	M5	19	7.5	9	1.17
MBPS-3502-AS1-A	2000	100	24	106	29	48	24.5	M8	M5	19	7.5	9	1.25
MBPS-3502-BS1-A	2000	100	24	106	29	48	24.5	M8	M5	19	7.5	9	1.25
MBPS-3502-DS1	2100	100	24	105.7	27.7	46	24.5	M8	G1/8	19	9	10	1.29
MBPS-3503-AS1	2600	100	24	105.7	27.7	46	24.5	M8	G1/8	19	9	10	1.31
MBPS-3504-BS1-A	2000	100	24	106	29	48	24.5	M8	M5	19	7.5	9	1.18
MBPS-3504-FS1	2600	100	24	105.7	27.7	46	24.5	M8	G1/8	19	9	10	1.31
MBPS-3505-AS1	2600	100	24	105.7	27.7	46	24.5	M8	G1/8	19	9	10	1.31
MBPS-3505-BS1	2600	100	24	105.7	27.7	46	24.5	M8	G1/8	19	9	10	1.32
MBPS-3510-BS1	2600	100	24	105.7	27.7	46	24.5	M8	G1/8	19	9	10	1.29
MBPS-3512-ES1-A	2000	100	24	106	29	48	24.5	M8	M5	19	7.5	9	1.26
MBPS-3512-FS1	2600	100	24	105.7	27.7	46	24.5	M8	G1/8	19	9	10	1.3
MBPS-3514-DS1	2600	100	24	105.7	27.7	46	24.5	M8	G1/8	19	9	10	1.3
MBPS-3514-ES1	2600	100	24	105.7	27.7	46	24.5	M8	G1/8	19	9	10	1.28

レールの呼び#55

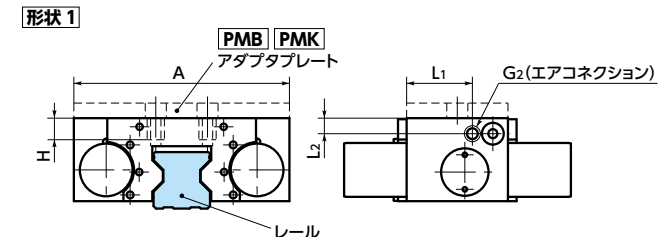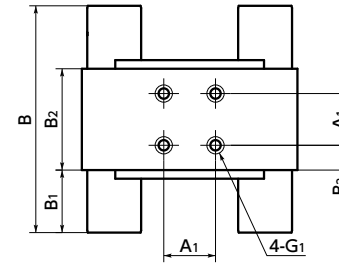

●クランプ部の形状は品番により異なります。各品番の形状は、CADデータをご確認ください。

単位:mm

品番	保持力 (N)	A	A1	B	B1	B2	B3	G1	G2	L1	L2	H	質量 (kg)
MBPS-4501-ES1	3600	120	26	113.2	32.2	49	24.5	M10	G1/8	31.1	15	15	2.07
MBPS-4502-BS1	3600	120	26	113.2	32.2	49	24.5	M10	G1/8	31.1	15	15	2.01
MBPS-4502-DS1	3100	120	26	113.2	32.2	49	24.5	M10	G1/8	31.1	15	15	2.05
MBPS-4503-AS1	3600	120	26	113.2	32.2	49	24.5	M10	G1/8	31.1	15	15	2.01
MBPS-4504-BS1	2600	120	26	108.7	27.7	49	24.5	M10	G1/8	16	8	14	1.66
MBPS-4504-FS1	3600	120	26	113.2	32.2	49	24.5	M10	G1/8	31.1	15	15	2.02
MBPS-4505-AS1	3600	120	26	113.2	32.2	49	24.5	M10	G1/8	31.1	15	15	2.06
MBPS-4505-BS1	3600	120	26	113.2	32.2	49	24.5	M10	G1/8	31.1	15	15	2.08
MBPS-4510-BS1	3600	120	26	113.2	32.2	49	24.5	M10	G1/8	31.1	15	15	1.98
MBPS-4512-FS1	3600	120	26	113.2	32.2	49	24.5	M10	G1/8	31.1	15	15	2.14
MBPS-4514-ES1	3600	120	26	113.2	32.2	49	24.5	M10	G1/8	31.1	15	15	2.1
MBPS-5501-AS1	3600	140	30	113.2	32.2	49	9.5	M10	G1/8	23	16	15	2.75
MBPS-5501-CS1	3600	140	30	113.2	32.2	49	9.5	M10	G1/8	23	16	15	2.6
MBPS-5501-ES1	4700	140	38	144	41	62	12	M10	G1/8	23	11	15	3.52
MBPS-5502-DS1	3500	140	38	144	41	62	12	M10	G1/8	23	11	15	3.67
MBPS-5503-AS1	4700	140	38	144	41	62	12	M10	G1/8	23	11	15	3.84
MBPS-5504-BS1	3600	140	30	113.2	32.2	49	9.5	M10	G1/8	23	16	15	3
MBPS-5504-FS1	4700	140	38	144	41	62	12	M10	G1/8	23	11	15	3.6
MBPS-5505-AS1	4700	140	38	144	41	62	12	M10	G1/8	23	11	15	3.62
MBPS-5505-BS1	4700	140	38	144	41	62	12	M10	G1/8	23	11	15	3.61
MBPS-5510-BS1	4700	140	38	144	41	62	12	M10	G1/8	23	11	15	3.67

●品番指定 ※価格・納期はNBKウェブサイトをご覧ください。

MBPS-2501-ES1

1

レバー位置変更

対応不可