



APS 高性能ショックアブソーバ(パワーストップ) - 長寿命・高エネルギー吸収タイプ

WEB 選定ナビ WEB CAD Download


M6 - M8

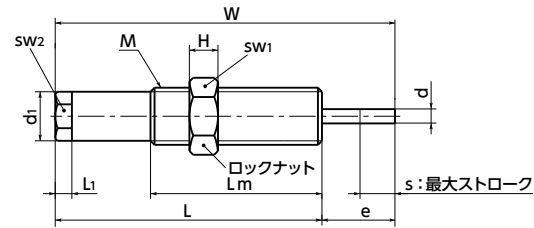

M10 - M27

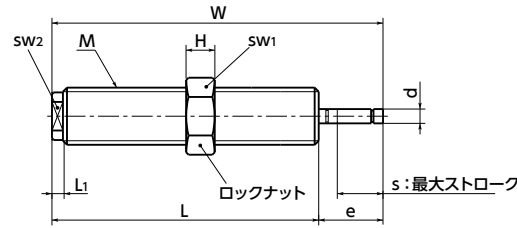

M33 M45

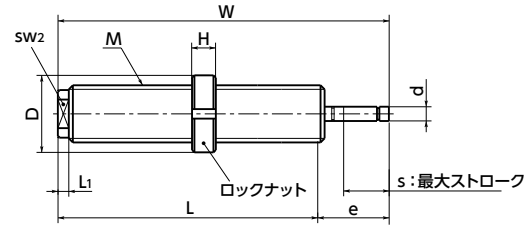

寸法

品番	M(細目)		L	L1	Lm	d	d1	e	W	H	sw1	D	sw2	質量 (g)
	ねじの呼び	ピッチ												
APS-M6-0.5	M6	0.5	30	1.8	18	1.4	5.4	8	38	3.2	10		4.5	6
APS-M8-1	M8	1	40	2.5	26	2.3	6.8	9.5	49.5	4	13		6	12
APS-M10-1	M10	1	51	2.3		3		11	62	5	13		8	25
APS-M12-1	M12	1	56	2.3		3		13.5	69.5	6	14		8	35
APS-M14-1	M14	1	66	3.5		4		17	83	8	17		10	65
APS-M14-1.5	M14	1.5	66	3.5		4		17	83	8	17		10	65
APS-M20-1.5	M20	1.5	76	4		6		19	95	10	24		14	135
APS-M20-1.5L	M20	1.5	97	4		6		34	131	10	24		14	180
APS-M25-1.5	M25	1.5	105	4		8		31	136	12	30		19	300
APS-M25-1.5L	M25	1.5	125	4		8		46	171	12	30		19	365
APS-M27-3	M27	3	105	4		8		31	136	12	32		19	370
APS-M33-1.5	M33	1.5	125	5		10		40	165	10		41	24	650
APS-M33-1.5L	M33	1.5	144	5		10		60	204	10		41	24	750
APS-M45-1.5	M45	1.5	140	6		12		30	170	10		60	36	1290
APS-M45-1.5L	M45	1.5	195	6		12		55	250	10		60	36	1740

●全商品にロックナット1個が付属しています。

性能

品番	最大吸収エネルギー (J)	緊急時最大吸収エネルギー (J)	時間あたり最大吸収エネルギー (J/h)	最大ストローク s (mm)	衝突速度 (m/s)		復帰時間 (s)	復帰力 (N)	
					min.	max.		min.	max.
APS-M6-0.5-S	1.5		3200	4	1.8	3.5	0.15	1	3
APS-M6-0.5-M	1.5		3200	4	0.8	2.2	0.15	1	3
APS-M8-1-S	3		8000	5	1.8	3.5	0.15	1	4
APS-M8-1-M	4		9000	5	0.8	2.2	0.15	1	4
APS-M8-1-H	4		9000	5	0.2	1.2	0.15	1	4
APS-M10-1-S	10		18000	8	1.8	3.5	0.15	4	10
APS-M10-1-M	12		20000	8	0.8	2.2	0.15	4	10
APS-M10-1-H	12		20000	8	0.2	1.2	0.15	4	10
APS-M12-1-S	16	22	30000	10	1.8	3.5	0.2	6	10
APS-M12-1-M	18	25	33000	10	0.8	2.2	0.2	6	10
APS-M12-1-H	18	27	33000	10	0.2	1.2	0.2	6	10
APS-M14-1-S	30	35	45000	12	1.8	3.5	0.2	8	15
APS-M14-1-M	32	40	50000	12	0.8	2.2	0.2	8	15
APS-M14-1-H	32	45	50000	12	0.2	1.2	0.2	8	15
APS-M14-1.5-S	30	35	45000	12	1.8	3.5	0.2	8	15
APS-M14-1.5-M	32	40	50000	12	0.8	2.2	0.2	8	15
APS-M14-1.5-H	32	45	50000	12	0.2	1.2	0.2	8	15
APS-M20-1.5-S	70	100	70000	15	1.8	3.5	0.3	15	30
APS-M20-1.5-M	80	120	80000	15	0.8	2.2	0.3	15	30
APS-M20-1.5-H	80	150	80000	15	0.2	1.2	0.3	15	30
APS-M20-1.5L-S	100	170	100000	30	1.8	3.5	0.5	10	25
APS-M20-1.5L-M	120	220	120000	30	0.8	2.2	0.5	10	25
APS-M25-1.5-S	190	350	100000	25	1.8	3.5	0.4	25	50
APS-M25-1.5-M	210	400	120000	25	0.8	2.2	0.4	25	50
APS-M25-1.5-H	210	450	120000	25	0.2	1.2	0.4	25	50
APS-M25-1.5L-S	250	500	135000	40	1.8	3.5	0.6	25	55
APS-M25-1.5L-M	350	750	150000	40	0.8	2.2	0.6	25	55
APS-M27-3-S	190	350	100000	25	1.8	3.5	0.4	25	50
APS-M27-3-M	210	400	120000	25	0.8	2.2	0.4	25	50
APS-M27-3-H	210	450	120000	25	0.2	1.2	0.4	25	50
APS-M33-1.5-S	300	500	120000	30	1.8	3.5	0.4	30	55
APS-M33-1.5-M	350	750	140000	30	0.8	2.2	0.4	30	55
APS-M33-1.5-H	350	850	140000	30	0.2	1.2	0.4	30	55
APS-M33-1.5L-S	450	1100	170000	50	1.8	3.5	0.8	30	55
APS-M33-1.5L-M	500	1200	180000	50	0.8	2.2	0.8	30	55
APS-M45-1.5-S	600	1400	150000	25	1.8	3.5	0.4	30	60
APS-M45-1.5-M	650	1500	170000	25	0.8	2.2	0.4	30	60
APS-M45-1.5-H	650	1600	170000	25	0.2	1.2	0.4	30	60
APS-M45-1.5L-S	1000	2600	200000	50	1.8	3.5	0.8	50	130
APS-M45-1.5L-M	1200	2800	220000	50	0.8	2.2	0.8	50	130
APS-M45-1.5L-H	1200	2800	220000	50	0.2	1.2	0.8	50	130

● 品番指定



APS-M20-1.5-S



価格はコンタクトセンターへお問い合わせください。