



M4 - M27

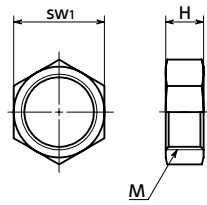

M33 M45

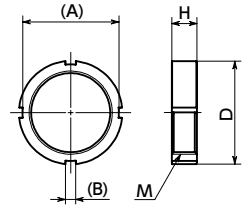

寸法

単位: mm

品番	M	H	sw1	D	A	B	適用パワーストップ		質量 (g)
							APS → P.xxxx	APR → P.xxxx	
ASMS-M4-0.5	M4x0.5	2	6				M4 - 0.5		0.5
ASMS-M5-0.5	M5x0.5	2	7				M5 - 0.5		0.5
ASMS-M6-0.5	M6x0.5	3.2	10				M6 - 0.5		2
ASMS-M8-0.75	M8x0.75	4	13				M8 - 0.75	M8 - 0.75	3
ASMS-M8-1	M8x1	4	13				M8 - 1	M8 - 1	3
ASMS-M10-1	M10x1	5	13				M10 - 1	M10 - 1	3
ASMS-M12-1	M12x1	6	14				M12 - 1	M12 - 1	5
ASMS-M14-1	M14x1	8	17				M14 - 1	M14 - 1	10
ASMS-M14-1.5	M14x1.5	8	17				M14 - 1.5	M14 - 1.5	10
ASMS-M20-1.5	M20x1.5	10	24				M20 - 1.5・M20 - 1.5L	M20 - 1.5	20
ASMS-M25-1.5	M25x1.5	12	30				M25 - 1.5・M25 - 1.5L	M25 - 1.5	35
ASMS-M27-1.5	M27x1.5	12	32				M27 - 1.5	M27 - 1.5	40
ASMS-M27-3	M27x3	12	32				M27 - 3	M27 - 3	40
ASMS-M33-1.5	M33x1.5	10		41	37	6	M33 - 1.5・M33 - 1.5L	M33 - 1.5	40
ASMS-M45-1.5	M45x1.5	10		60	55	8	M45 - 1.5・M45 - 1.5L	M45 - 1.5	100

● 品番指定

直送 14時当日出荷

ASMS-M10-1



価格はコンタクトセンターへお問い合わせください