


# 3V-2 ウェッジプーリー - 3V・3VX適用

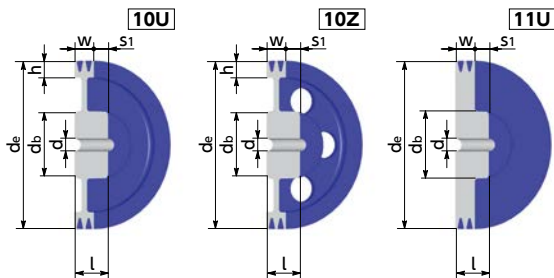

単位: mm

品番	ピッチ径 dp	外径 de	最大軸穴径 d	下穴径 d	形状 図番	ハブ				リム		慣性モーメント (kg・m <sup>2</sup> )	質量 (kg)
						db	l	s1	s2	w	h <sup>+3</sup> <sub>0</sub>		
56-3V-2	54.8	57	22	-	11U	40	35	7.3	-	27.7	-	0.000145	0.46
60-3V-2	58.8	61	24	-	11U	45	35	7.3	-	27.7	-	0.000199	0.55
67-3V-2	65.8	68	28	-	11U	50	35	7.3	-	27.7	-	0.000317	0.7
71-3V-2	69.8	72	30	-	11U	50	35	7.3	-	27.7	-	0.000397	0.78
75-3V-2	73.8	76	32	-	11U	58	35	7.3	-	27.7	-	0.000521	0.9
80-3V-2	78.8	81	35	-	11U	58	35	7.3	-	27.7	-	0.000666	1.01
85-3V-2	83.8	86	35	-	11U	58	35	7.3	-	27.7	-	0.000845	1.14
90-3V-2	88.8	91	35	-	11U	58	35	7.3	-	27.7	-	0.00106	1.27
95-3V-2	93.8	96	35	-	11U	58	35	7.3	-	27.7	-	0.00133	1.41
100-3V-2	98.8	101	38	-	11U	63	35	7.3	-	27.7	-	0.00166	1.59
110-3V-2	108.8	111	38	-	11U	63	35	7.3	-	27.7	-	0.00244	1.91
112-3V-2	110.8	113	38	-	11U	63	35	7.3	-	27.7	-	0.00263	1.97
120-3V-2	118.8	121	45	-	11U	76	42	14.3	-	27.7	-	0.00375	2.57
125-3V-2	123.8	126	45	-	11U	76	42	14.3	-	27.7	-	0.00438	2.76
130-3V-2	128.8	131	45	-	11U	76	42	14.3	-	27.7	-	0.0051	2.96
140-3V-2	138.8	141	45	-	11U	76	42	14.3	-	27.7	-	0.00683	3.37
150-3V-2	148.8	151	42	-	10U	76	42	14.3	-	27.7	17.5	0.00706	3.02
160-3V-2	158.8	161	42	-	10U	76	42	14.3	-	27.7	17.5	0.00885	3.26
180-3V-2	178.8	181	48	-	10U	86	48	20.3	-	27.7	17.5	0.0141	4.33
200-3V-2	198.8	201	48	-	10U	86	48	20.3	-	27.7	17.5	0.0207	4.99
212-3V-2	210.8	213	55	-	10U	100	48	20.3	-	27.7	17.5	0.0274	6.06
224-3V-2	222.8	225	55	-	10U	100	48	20.3	-	27.7	17.5	0.0332	6.48
236-3V-2	234.8	237	55	-	10U	100	48	20.3	-	27.7	17.5	0.0399	6.92
250-3V-2	248.8	251	55	-	10Z	100	48	20.3	-	27.7	17.5	0.0467	7.05
280-3V-2	278.8	281	55	-	10Z	100	55	27.3	-	27.7	17.5	0.0667	8.09
300-3V-2	298.8	301	55	-	10Z	100	55	27.3	-	27.7	17.5	0.086	8.82
315-3V-2	313.8	316	55	-	10Z	100	55	27.3	-	27.7	17.5	0.103	9.36
355-3V-2	353.8	356	55	-	10Z	100	55	27.3	-	27.7	17.5	0.16	11
400-3V-2	398.8	401	55	-	10Z	100	55	27.3	-	27.7	17.5	0.243	12.6
450-3V-2	448.8	451	55	-	10Z	100	55	27.3	-	27.7	17.5	0.394	15.5
500-3V-2	498.8	501	55	-	10Z	100	55	27.3	-	27.7	17.5	0.715	22.5

## 追加工サービスをご利用ください。

Vプーリーに軸穴・キー溝・押しねじ穴の  
追加工をいたします。実働1日目出荷。



● 軸穴・キー溝・押しねじ追加工

対応可・別料金

● 品番指定 ※価格・納期はNBKウェブサイトをご覧ください。

## 120-3V-2

