


5V-10 ウェッジプーリー - 5V・5VX適用

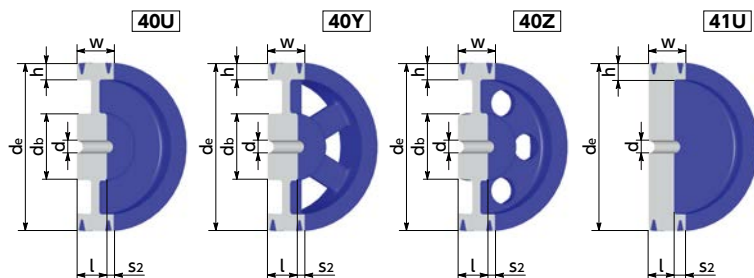

単位: mm

品番	ピッチ径 dp	外径 de	最大軸穴径 d	下穴径 d	形状 図番	ハブ				リム		慣性モーメント (kg・m ²)	質量 (kg)
						db	l	s1	s2	w	h ₀ ⁺³		
180-5V-10	177.4	181	90	48	41U	-	110	-	72.9	182.9	26	0.0846	20.4
200-5V-10	197.4	201	95	48	41U	-	110	-	72.9	182.9	26	0.13	25.5
212-5V-10	209.4	213	100	48	41U	-	110	-	72.9	182.9	26	0.166	28.8
220-5V-10	217.4	221	105	48	41U	-	130	-	52.9	182.9	24	0.201	33.8
224-5V-10	221.4	225	105	48	41U	-	130	-	52.9	182.9	26	0.22	35.5
230-5V-10	227.4	231	110	48	41U	-	130	-	52.9	182.9	23	0.24	36.9
236-5V-10	233.4	237	110	48	41U	-	130	-	52.9	182.9	26	0.273	39.7
240-5V-10	237.4	241	115	48	41U	-	130	-	52.9	182.9	26	0.293	41.2
250-5V-10	247.4	251	120	48	41U	-	130	-	52.9	182.9	26	0.347	44.9
260-5V-10	257.4	261	125	48	41U	-	130	-	52.9	182.9	23.5	0.403	48.4
265-5V-10	262.4	266	130	48	41U	-	130	-	52.9	182.9	26	0.444	51
280-5V-10	277.4	281	140	54	41U	-	130	-	52.9	182.9	26	0.556	56.8
300-5V-10	297.4	301	95	54	40U	170	130	-	52.9	182.9	26	0.515	46.1
315-5V-10	312.4	316	100	54	40U	180	140	-	42.9	182.9	26	0.624	52.2
335-5V-10	332.4	336	100	54	40U	180	140	-	42.9	182.9	26	0.769	56.4
355-5V-10	352.4	356	110	54	40U	200	140	-	42.9	182.9	26	0.973	65
375-5V-10	372.4	376	110	54	40U	200	140	-	42.9	182.9	26	1.16	68.9
400-5V-10	397.4	401	110	58	40Z	200	160	-	22.9	182.9	26	1.4	75.1
425-5V-10	422.4	426	110	58	40Z	200	160	-	22.9	182.9	26	1.7	79.6
450-5V-10	447.4	451	110	58	40Z	200	160	-	22.9	182.9	26	2.03	83.6
475-5V-10	472.4	476	110	58	40Z	200	160	-	22.9	182.9	26	2.36	85.8
500-5V-10	497.4	501	110	58	40Z	200	160	-	22.9	182.9	26	2.97	96.3
600-5V-10	597.4	601	110	58	40Y	200	160	-	22.9	182.9	26	4.76	106
630-5V-10	627.4	631	110	58	40Y	200	160	-	22.9	182.9	28	5.39	116
710-5V-10	707.4	711	110	58	40Y	200	160	-	22.9	182.9	28	8.63	130
750-5V-10	747.4	751	110	58	40Y	200	160	-	22.9	182.9	26	9.54	131
800-5V-10	797.4	801	110	58	40Y	200	160	-	22.9	182.9	28	12.6	147
900-5V-10	897.4	901	110	58	40Y	200	165	-	17.9	182.9	28	18.4	167
1000-5V-10	997.4	1001	120	65	40Y	220	180	-	2.9	182.9	28	25.9	197
1250-5V-10	1247.4	1251	120	65	40Y	220	180	-	2.9	182.9	28	52.3	248

追加工サービスをご利用ください。

Vプーリーに軸穴・キー溝・押しねじ穴の
追加工をいたします。実働1日目出荷。



● 軸穴・キー溝・押しねじ追加工

対応可・別料金

● 品番指定 ※価格・納期はNBKウェブサイトをご覧ください。

630-5V-10

