


5V-8 ウェッジプーリー - 5V・5VX適用

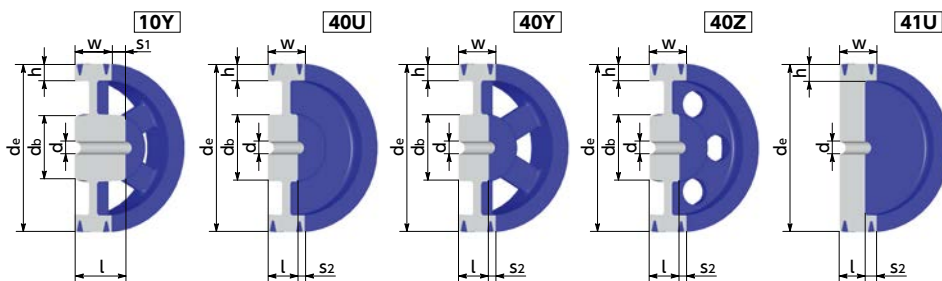

単位: mm

品番	ピッチ径 d_p	外径 d_e	最大軸穴径 d	下穴径 d	形状 図番	ハブ				リム		慣性モーメント ($\text{kg} \cdot \text{m}^2$)	質量 (kg)
						d_b	l	s_1	s_2	w	$h+3/0$		
180-5V-8	177.4	181	90	35	41U	-	110	-	37.9	147.9	26	0.0733	19
190-5V-8	187.4	191	90	35	41U	-	110	-	37.9	147.9	26	0.0919	21.4
200-5V-8	197.4	201	95	35	41U	-	110	-	37.9	147.9	26	0.114	23.8
210-5V-8	207.4	211	100	35	41U	-	110	-	37.9	147.9	25	0.139	26.3
212-5V-8	209.4	213	100	35	41U	-	110	-	37.9	147.9	26	0.145	27
220-5V-8	217.4	221	105	35	41U	-	110	-	37.9	147.9	24	0.167	28.9
224-5V-8	221.4	225	105	35	41U	-	110	-	37.9	147.9	26	0.183	30.3
230-5V-8	227.4	231	110	48	41U	-	110	-	37.9	147.9	23	0.199	30.9
236-5V-8	233.4	237	110	48	41U	-	110	-	37.9	147.9	26	0.226	33.1
240-5V-8	237.4	241	115	48	41U	-	110	-	37.9	147.9	26	0.242	34.3
250-5V-8	247.4	251	120	48	41U	-	110	-	37.9	147.9	26	0.287	37.5
260-5V-8	257.4	261	125	48	41U	-	110	-	37.9	147.9	23.5	0.335	40.4
265-5V-8	262.4	266	130	48	41U	-	110	-	37.9	147.9	26	0.368	42.6
280-5V-8	277.4	281	90	48	40U	160	130	-	17.9	147.9	26	0.334	36.5
300-5V-8	297.4	301	90	48	40U	160	130	-	17.9	147.9	26	0.42	39.5
315-5V-8	312.4	316	100	54	40U	180	130	-	17.9	147.9	26	0.51	44.5
335-5V-8	332.4	336	100	54	40U	180	140	-	7.9	147.9	26	0.638	49.9
355-5V-8	352.4	356	100	54	40Z	180	140	-	7.9	147.9	26	0.739	51
375-5V-8	372.4	376	100	54	40Z	180	140	-	7.9	147.9	26	0.87	53.2
400-5V-8	397.4	401	100	54	40Z	180	140	-	7.9	147.9	26	1.1	58.2
425-5V-8	422.4	426	100	54	40Z	180	140	-	7.9	147.9	26	1.32	60.3
450-5V-8	447.4	451	100	54	40Z	180	140	-	7.9	147.9	26	1.58	63.4
475-5V-8	472.4	476	100	54	40Z	180	140	-	7.9	147.9	26	1.96	69.7
500-5V-8	497.4	501	100	54	40Z	180	140	-	7.9	147.9	26	2.33	73.5
530-5V-8	527.4	531	100	54	40Z	180	140	-	7.9	147.9	26	2.84	78.5
560-5V-8	557.4	561	100	54	40Y	180	140	-	7.9	147.9	26	3.06	77.8
600-5V-8	597.4	601	100	54	40Y	180	140	-	7.9	147.9	26	3.8	82.7
630-5V-8	627.4	631	100	54	40Y	180	140	-	7.9	147.9	28	4.74	90.2
710-5V-8	707.4	711	100	58	40Y	180	140	-	7.9	147.9	28	6.95	102
750-5V-8	747.4	751	100	58	40Y	180	140	-	7.9	147.9	26	7.69	103
800-5V-8	797.4	801	110	58	10Y	200	160	12.1	-	147.9	28	10.3	125
900-5V-8	897.4	901	110	58	10Y	200	160	12.1	-	147.9	28	15	142
1000-5V-8	997.4	1001	110	58	10Y	200	160	12.1	-	147.9	28	21.1	159
1250-5V-8	1247.4	1251	110	65	10Y	200	160	12.1	-	147.9	28	42.8	202

追加工サービスをご利用ください。

Vプーリーに軸穴・キー溝・押しねじ穴の
追加工をいたします。実働1日目出荷。



● 軸穴・キー溝・押しねじ追加工

対応可・別料金

● 品番指定 ※価格・納期はNBKウェブサイトをご覧ください。

630-5V-8

